


## K40P332 Product Details

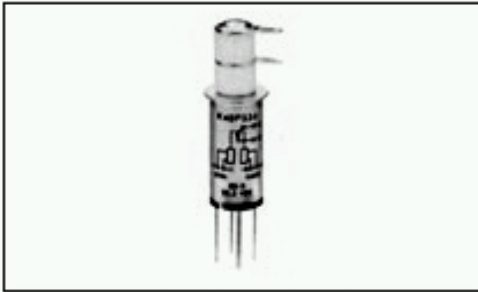

### K40P332 (1618239-7)

TE Internal Number: 1618239-7

✓ Active

[Add to Part List](#)

### High Voltage Relays

[Not EU RoHS or ELV Compliant](#)

#### Product Highlights:

- Contact Arrangement = 1 Form P, SPST-Latching, 1 Latching
- Power Switching = Make Only, Yes, No
- Contact Current Rating = 0 - 35 Amps.
- RF Rated
- Coil Voltage = 26.5 VDC

[View all Features](#) | [Find Similar Products](#)

### Quick Links

- ▶ [Check Pricing & Availability](#)
- ▶ [Search for Tooling](#)
- ▶ [Product Feature Selector](#)
- ▶ [Contact Us About This Product](#)
- ▶ [Request Samples](#)

**NEW!**

### Documentation & Additional Information

#### Product Drawings:

- None Available

#### Catalog Pages/Data Sheets:

- None Available

#### Product Specifications:

- None Available

#### Application Specifications:

- None Available

#### Instruction Sheets:

- None Available

#### CAD Files:

- None Available

#### Additional Information:

- [Product Line Information](#)

#### Related Products:

- [Tooling](#)

### Product Features (Please use the Product Drawing for all design activity)

#### Product Type Features:

- [Termination Style](#) = Bus Wire

#### Electrical Characteristics:

- [Contact Current Rating \(Amps.\)](#) = 0 - 35
- [RF Rated](#) = Yes
- [Coil Voltage \(VDC\)](#) = 26.5
- [Voltage, Max. \(VDC\)](#) = 0 - 5000
- Current, Carry Only = Yes

#### Termination Related Features:

- [High Voltage Connection \(Power\)](#) = High Voltage Tab
- [High Voltage Connection \(Coil\)](#) = Bus Wire
- [Auxiliary Contacts](#) = Without

#### Body Related Features:

- [Mount Style](#) = Flanged

#### Configuration Related Features:

- [Contact Arrangement](#) = 1 Form P, SPST-Latching, 1 Latching
- [Power Switching](#) = Make Only, Yes, No
- [Economizer](#) = Without

#### Industry Standards:

- [RoHS/ELV Compliance](#) = Not ELV/RoHS compliant
- [Lead Free Solder Processes](#) = Not suitable for lead free processing

#### Other:

- Brand = Kilovac