

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: **0192020054**
Status: **Active**
Overview: Splices
Description: NylaKrimp™ Butt Splice for 8 AWG Wire

Documents:

Drawing (PDF) Product Specification PS-19902-013-001 (PDF)
Product Specification PS-19902-011-001 (PDF) RoHS Certificate of Compliance (PDF)

Agency Certification

CSA LR18689
 UL E32244

General

Product Family Splices
 Series 19202
 Crimp Quality Equipment Yes
 Mil-Spec N/A
 Overview Splices
 Product Name Butt, NylaKrimp™
 UPC 800753048294

Physical

Barrel Type Closed - Brazed
 Color - Resin Red
 Flammability 94V-2
 Insulation Nylon (PA)
 Material - Metal Copper
 Material - Plating Mating Tin
 Material - Plating Termination Tin
 Net Weight 5.122/g
 Packaging Type Bag
 Temperature Range - Operating -55°C to +105°C
 Wire Insulation Diameter 6.73mm max.
 Wire Size AWG 8

Electrical


Voltage - Maximum 300V

Material Info

Engineering Number D-754

Reference - Drawing Numbers

Product Specification PS-19902-011-001, PS-19902-013-001
 Sales Drawing D754CD

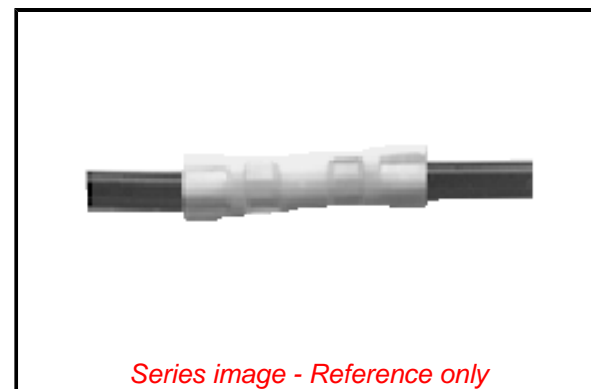

EU ELV

Not Relevant

EU RoHS

Not Reviewed

REACH SVHC

Not Reviewed

Halogen-Free

Status

Not Reviewed

Need more information on product environmental compliance?

Email productcompliance@molex.com
 Please visit the [Contact Us](#) section for any non-product compliance questions.

| | |
|-----------------|--------------|
| China ROHS | Not Relevant |
| ELV | Not Relevant |
| RoHS Phthalates | Not Reviewed |

Search Parts in this Series

19202 Series