

REV. 0


DCO 15961

TOLERANCES = ±.010

COIL: @ 25°C	RESISTANCE	27 OHMS ±10%
	NOMINAL VOLTAGE	5.0 VDC
	MUST OPERATE	2.7 VDC
	MUST RELEASE	1.65 VDC MAX, 0.29 VDC MIN.

ENVIRONMENT:		
VIBRATION	10	CPS TO 3000 CPS @ 30 g's
SHOCK	100	g's 6 MS. DURATION
TEMPERATURE	-65	°C TO +125 °C
NOTES: OPERATE & RELEASE 4 MS MAX.		
CONTACT BOUNCE 2.0 MS MAX.		
CONTACT STABILIZATION 2.0 MS MAX.		
ALL OTHER REQUIREMENTS TO MIL-R-39016 LEVEL M		

CUSTOMER DATA SHEET

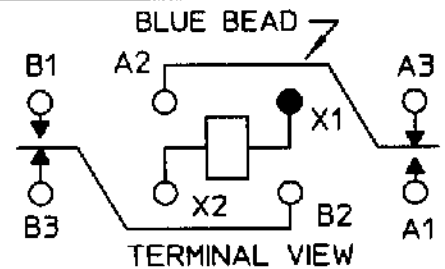

CONTACT RATING: LOW LEVEL TO 2A
28 VDC RESISTIVE 100,000 OPERATIONS

DR. B.D. 12/6/99 CK. SAH 12/6/99

COMMUNICATIONS INSTRUMENTS, INC.

CUST. QPL
CUST. NO. M39016/6-147M REV. ----

"HFW" RELAY

HFW1230L03M