

**PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION**

**Part Number:** [1300990095](#)  
**Status:** **Active**  
**Overview:** Strain-Relief Cord Grips  
**Description:** MAX-LOC Strain Relief Cord-Sealing Grip, 3/4" NPT, 90° Angle Male, Cable Diameter 11.10-14.27mm (.437-.562"), Non-Metallic Mesh

**Documents:**

[Drawing \(PDF\)](#) [Product Literature \(PDF\)](#)  
[RoHS Certificate of Compliance \(PDF\)](#)

**Agency Certification**

CSA LR32159  
 UL E76954

**General**

Product Family Cable Grips  
 Series [130099](#)  
 Eye Type N/A  
 NEMA Rating NEMA 3R  
 O-Ring No  
 Overview [Strain-Relief Cord Grips](#)  
 Product Literature Order No 987651-6081  
 Product Name MAX-LOC®  
 Type Strain Relief Grip  
 UPC 78678855375  
 Use With 3/4" NPT MAX-LOC Lock Nut [130099-0144](#) , 3/4" NPT MAX-LOC Gasket Sealing Ring [130099-0150](#) , 3/4" NPT MAX-LOC O-Ring [130180-0333](#)  
 Woodhead Yes

**Physical**


Approximate Break Strength N/A  
 Bale Length N/A  
 Body Style 90° Angle  
 Cable Diameter 11.10-14.27mm (.437-.562")  
 Color - Grommet N/A  
 Gender Male  
 Material - Body Nylon  
 Material - Grip Nylon  
 Mesh Length N/A  
 Number of Holes 1  
 Thread Size 3/4" NPT

**Material Info**

Engineering Number 5537NM

**Reference - Drawing Numbers**

Sales Drawing SD-130099-006

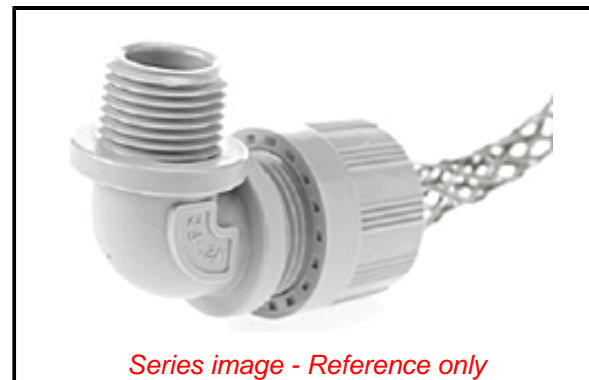

*Series image - Reference only*

**EU ELV**

**Not Reviewed**

**EU RoHS**

**Not Reviewed**

**REACH SVHC**

Not Reviewed

**Halogen-Free**

**Status**

**Not Reviewed**

**Need more information on product environmental compliance?**

Email [productcompliance@molex.com](mailto:productcompliance@molex.com)  
 Please visit the [Contact Us](#) section for any non-product compliance questions.

China ROHS Not Reviewed  
 ELV Not Reviewed  
 RoHS Phthalates Not Reviewed

**Search Parts in this Series**

[130099 Series](#)