

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [0190990032](#)
Status: **Active**
Overview: Solderless Terminals
Description: InsulKrimp™ Snap Spade Terminal for 14-16 AWG Wire, Blue

Documents:

[Drawing \(PDF\)](#) [Product Specification PS-19902-013-001 \(PDF\)](#)
[Product Specification PS-19902-009-001 \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)
[Product Specification PS-19902-011-001 \(PDF\)](#)

Agency Certification

CSA LR18689
 UL E32244

General

Product Family Ring and Spade Terminals
 Series [19099](#)
 Crimp Quality Equipment Yes
 Mil-Spec N/A
 Overview [Solderless Terminals](#)
 Product Name InsulKrimp™
 Type Spade Snap
 UPC 800753089181

Physical

Barrel Type Closed
 Color - Resin Blue
 Flammability 94V-0
 Insulation PVC
 Material - Plating Mating Tin
 Net Weight 0.811/g
 Packaging Type Bag
 Stud Size 8 (M4)
 Wire Insulation Diameter 4.40mm max.
 Wire Size AWG 14, 16
 Wire Size mm² 1.30-2.00

Solder Process Data


Lead-freeProcess Capability N/A

Material Info

Engineering Number BB-2716-08X

Reference - Drawing Numbers

Product Specification PS-19902-009-001, PS-19902-011-001,
 PS-19902-013-001
 Sales Drawing BB-2716-08X

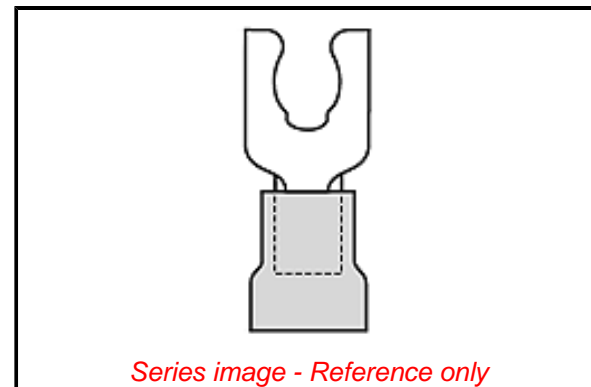

Series image - Reference only

EU ELV

Not Relevant

EU RoHS

Compliant

REACH SVHC

Not Contained Per -
 ED/30/2017 (7 July
 2017)

Halogen-Free

Status

Not Low-Halogen

**Need more information on product
 environmental compliance?**

Email productcompliance@molex.com
 Please visit the [Contact Us](#) section for any
 non-product compliance questions.

| | |
|-----------------|---------------|
| China ROHS | Green Image |
| ELV | Not Relevant |
| RoHS Phthalates | Not Contained |

Search Parts in this Series

[19099 Series](#)

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION