


521135-1 Product Details

Live Product Chat US Only
8:30am - 5pm ET, Mon - Fri

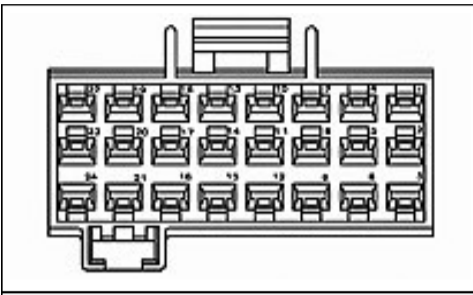

521135-1

Active

Timer Connectors

[Always EU RoHS/ELV Compliant](#) ([Statement of Compliance](#))

Product Highlights:

- Receptacle Housing
- Connector Type = Standard Timer
- Number of Positions = 24
- Housing Color = Black
- Not Sealed

[View all Features](#) | [Find Similar Products](#)

Quick Links

- [Check Pricing & Availability](#)
- [Search for Tooling](#)
- [Product Feature Selector](#)
- [Contact Us About This Product](#)

Documentation & Additional Information

Product Drawings:

- [HOUSING, 24 POSITION, SIDE LATCHED, TIMER CONNECTOR](#) (PDF, English)

Catalog Pages/Data Sheets:

- None Available

Product Specifications:

- None Available

Application Specifications:

- [Standard Timer Connectors](#) (PDF, English)

Instruction Sheets:

- None Available

CAD Files:

- None Available

Related Products:

- [Tooling](#)

[List all Documents](#)

Product Features (Please use the Product Drawing for all design activity)

Product Type Features:

- Product Type = Receptacle Housing
- [Connector Type](#) = Standard Timer
- Number of Positions = 24
- Sealed = No
- Comment = Housing accepts 3.18 [.125] blade receptacles P/N 770642-1; See customer drawing for differences

Housing Related Features:

- Housing Color = Black
- Housing Material = Nylon 66

Industry Standards:

- [RoHS/ELV Compliance](#) = RoHS compliant, ELV compliant
- [Lead Free Solder Processes](#) = Not relevant for lead free process
- RoHS/ELV Compliance History = Always was RoHS compliant

Other:

- Brand = AMP