


5552960 -2 Product Details

Live Product Chat US Only
8:30am - 5pm ET, Mon - Fri

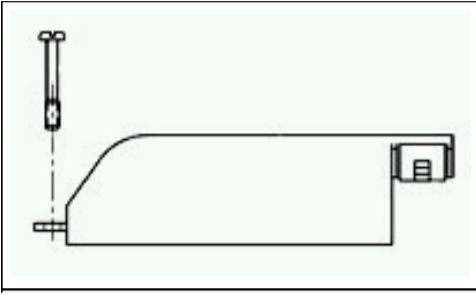

5552960 -2

Active

2.16 [.085] Accessories and Hardware

[Always EU RoHS/ELV Compliant](#) ([Statement of Compliance](#))

Product Highlights:

- ? Cover/Cable Clamp Kit
- ? Cover Type = Strain Relief
- ? Cover Style = Standard
- ? Slide -On Cover/Strain Relief Retention Method
- ? 90° Cable Exit Angle

[View all Features](#) | [Find Similar Products](#)

Quick Links

- [Check Pricing & Availability](#)
- [Search for Tooling](#)
- [Product Feature Selector](#)
- [Contact Us About This Product](#)

Documentation & Additional Information

Product Drawings:

- ? [COVER KIT, 90 DEGREES, 50 POSITION, SCREW LOCK, CHAMP](#) (PDF, English)

Catalog Pages/Data Sheets:

- ? None Available

Product Specifications:

- ? None Available

Application Specifications:

- ? None Available

Instruction Sheets:

- ? None Available

CAD Files:

- ? None Available

Additional Information:

- ? [Product Line Information](#)

Related Products:

- ? [Tooling](#)

[List all Documents](#)

Product Features

(Please use the Product Drawing for all design activity)

Product Type Features:

- ? [Product Type](#) = Cover/Cable Clamp Kit
- ? Cover Type = Strain Relief
- ? Cover Style = Standard
- ? [Number of Positions](#) = 50
- ? [Cable Outer Diameter \(mm \[in\]\)](#) = 8.89 – 10.80 [0.350 – 0.425]
- ? Color = Black

Mechanical Attachment:

- ? [Cover/Strain Relief Retention Method](#) = Slide - On

Body Related Features:

- ? [Cable Exit Angle](#) = 90°

Industry Standards:

- ? [RoHS/ELV Compliance](#) = RoHS compliant, ELV compliant
- ? [Lead Free Solder Processes](#) = Not relevant for lead free process
- ? RoHS/ELV Compliance History = Always was RoHS compliant

Operation/Application:

- ? [Application](#) = Cable -to -Cable

Packaging Related Features:

- ? Packaging Quantity = 100 Kits
- ? Packaging Method = Bulk

Other:

- ? Brand = AMP