


REV. 0

DCO 170284

COIL: @ 25°C	
RESISTANCE	552 OHMS ±10%
NOMINAL VOLTAGE	20.0 - 29.5 VDC
MUST OPERATE	13.5 VDC
MUST RELEASE	7.0 VDC MAX., 1.5 VDC MIN.

ENVIRONMENT:	
VIBRATION	55 CPS TO 2000 CPS @ 15 g's
SHOCK	50 g's 11 MS. DURATION
TEMPERATURE	-65 °C TO +125 °C
NOTES:	OPERATE 6 MS MAX. RELEASE 5 MS MAX.
DIELECTRIC 1000 VAC. BOUNCE 2.5 MS MAX.	

CUSTOMER DATA SHEET

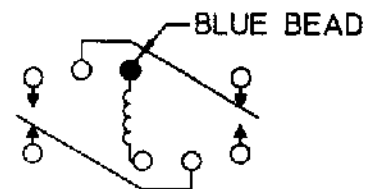

TERMINAL VIEW

CONTACT RATING:  
2 AMPS @ 28 VDC, 100,000 OPERATIONS

DR. B.D. 10/5/00 CK. TLG 10-9-00

**CIL Technologies™**  
advanced control electronic solutions

CUST CIL STD.  
CUST. NO. REV.

3SAE RELAY

REVISION  
R3SAE5014K1