

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [64001-6200](#)
Status: **Active**
Description: HAND CRIMP TOOL

Documents:

[RoHS Certificate of Compliance \(PDF\)](#)


General

Product Family	Application Tooling
Series	T0102
Comments	Field Repair, See Tooling Specification (PDF) Above
Function	Crimp
Geographic Area	Global
Level of Automation	Manual
More Detailed Tech Information	applicationtooling@molex.com
Product Name	PremiumGrade™
Survey	www.molex.com//review/apptool_survey.html
Tool Type	Handtool

Material Info

Reference - Drawing Numbers

Application Tooling Documents	ATS-640016200, TM-640160065, TM-640160065CN, TM-640160065DE, TM-640160065FR, TM-640160065IT, TM-640160065JP, TM-640160065KR, TM-640160065MY, TM-640160065PL, TM-640160065RU, TM-640160065SK, TM-640160065SP, TM-640160065TH, TM-640160065TW, TM-640160065VN
-------------------------------	---

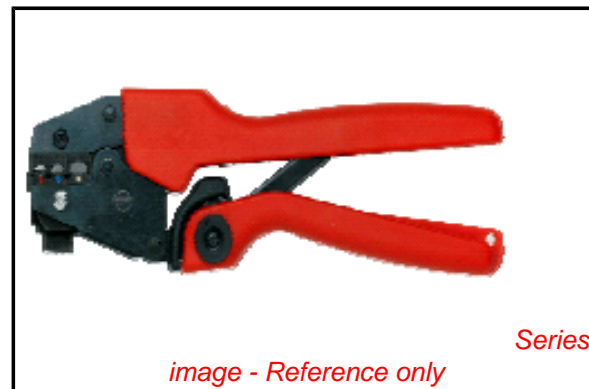

EU RoHS **China RoHS**

Compliance Status

Not Reviewed

REACH SVHC

Not Reviewed

Low-Halogen Status

Not Reviewed

Need more information on product environmental compliance?

Email productcompliance@molex.com
 For a multiple part number RoHS Certificate of Compliance, [click here](#)

Please visit the [Contact Us](#) section for any non-product compliance questions.

Search Parts in this Series

[T0102Series](#)

Use With

Loose Piece Terminals

Application Tooling | **FAQ**
Description | **Product #**

InsulKrimp™ Fully Insulated Piggyback Quick Disconnect, Tab 6.35 x 0.81mm, 10-12 AWG, Blue Insulator, Loose in a Bag	0190130033
InsulKrimp™ Piggyback Quick Disconnect, Tab 6.35 x 0.81mm, 14-16 AWG, Blue Insulator, Tape	0190110037
InsulKrimp™ Piggyback Quick Disconnect, Tab 6.35 x 0.81mm, 18-22	0190110035

AWG, Red Insulator,
Loose
InsulKrimp™ 0190110039
Piggyback Quick
Disconnect, Tab
6.35 x 0.81mm,
10-12 AWG, Yellow
Insulator, Tape

This document was generated on 04/02/2012

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION