

**PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION**

**Part Number:** [1302990300](#)  
**Status:** **Active**  
**Overview:** Brad Micro-Change (M12) Connectors  
**Description:** Brad Micro-Change (M12) Harsh-Duty Receptacle, 5 Pole, A-Code, Right-Angle

**Documents:**

[Drawing \(PDF\)](#) [Packaging Specification PK-130299-001 \(PDF\)](#)  
[Product Specification PS-130299-001-001 \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)

**General**

Product Family	Industrial Receptacles
Series	<a href="#">130299</a>
IP Rating	IP67
Overview	<a href="#">Brad Micro-Change (M12) Connectors</a>
Product Name	Micro-Change (M12)
Type	PCB Mount
UPC	78172513054

**Physical**

Coupling Type	Internal Thread
Gender	Female
Keyway	A-coded
Length	N/A
Material - Component	Nickel-plated Zinc Die-Cast
Mounting Thread Size	M12 x 1.0
Orientation	90° Angle
Panel Mount	Back, Front
Poles	5
Temperature Range - Operating	-40°C to +85°C
Wire Size AWG	N/A
Wire/Cable Type	N/A


**Electrical**

Current - Maximum per Contact	4.0A
Voltage - Maximum	250V AC/DC

**Material Info**

**Reference - Drawing Numbers**

Packaging Specification	PK-130299-001
Product Specification	PS-130299-001-001
Sales Drawing	SD-130299-007

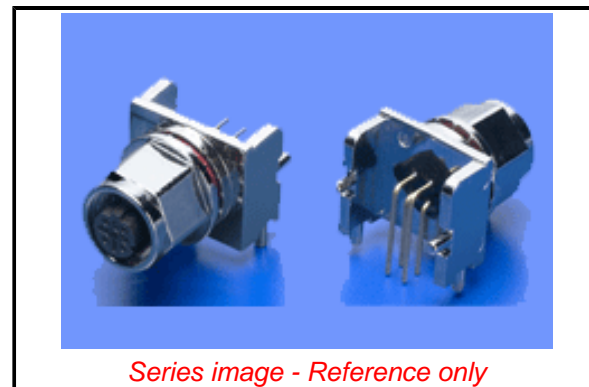

**EU ELV**

**Not Reviewed**

**EU RoHS**

**Not Reviewed**

**REACH SVHC**

Not Reviewed

**Halogen-Free**

**Status**

**Not Reviewed**

For more information, please visit [Contact US](#)

China ROHS

Not Reviewed

ELV

Not Reviewed

RoHS Phthalates

Not Reviewed

**China RoHS**

**Search Parts in this Series**

[130299 Series](#)

**Mates With**

Male A-Code Cable Assembly