

**PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION**

**Part Number:** [1200661575](#)  
**Status:** **Active**  
**Overview:** Brad Micro-Change (M12) Connectors  
**Description:** Micro-Change (M12) Double-Ended Cordset, 8 Poles, Female (Straight) to Male (Straight), 24 AWG, 3.0m (9.84') Length

**Documents:**

[Drawing \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)

**General**

Product Family	Industrial Cordsets
Series	<a href="#">120066</a>
Connector End A	Micro-Change (M12)
Connector End B	Micro-Change (M12)
IP Rating	IP67
Material - Contact	Brass
Overview	<a href="#">Brad Micro-Change (M12) Connectors</a>
Product Name	Micro-Change (M12)
Type	Double Ended
UPC	78678807100

**Physical**

Cable Diameter	6.10mm (.240")
Cable Length	3.0m (9.84')
Color - Cable Jacket	Yellow
Coupling Style	Threaded
Gender	Female-Male
Keyway	A-coded
LED Indicator	No
Material - Cable Jacket	PVC
Material - Connector Body	TPU
Material - Coupling Nut	Nickel-plated Brass
Material - O-Ring	Fluoro-elastomer
Material - Plating Mating	Gold
Net Weight	186.217/kg
Orientation	Straight to Straight
Poles	8
Temperature Range - Operating	-25°C to +85°C
Wire Size AWG	24
Wire/Cable Type	Shielded PVC

**Electrical**


Current - Maximum per Contact	2.0A
Voltage - Maximum	30V

**Material Info**

Engineering Number	888030S19M030
--------------------	---------------

**Reference - Drawing Numbers**

Sales Drawing	1200668165-000
---------------	----------------

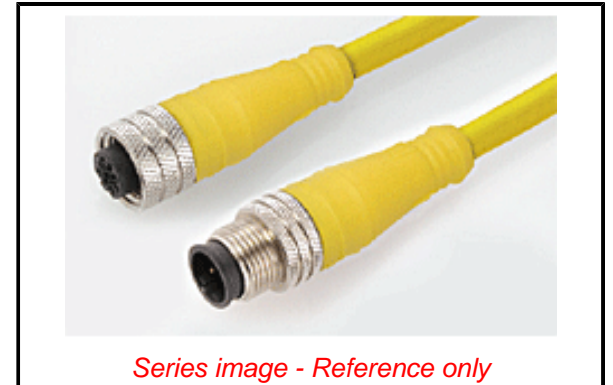

**EU ELV**

**Not Reviewed**

**EU RoHS**

**Not Reviewed**

**REACH SVHC**

Not Reviewed

**Halogen-Free**

**Status**

**Not Reviewed**

For more information, please visit [Contact US](#)

China ROHS

Not Reviewed

ELV

Not Reviewed

RoHS Phthalates

Not Reviewed

**Search Parts in this Series**

[120066 Series](#)