

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [1200710089](#)
Status: **Active**
Overview: Brad Micro-Change (M12) Connectors
Description: Micro-Change (M12) Field Attachable Connector, 4 Poles, Straight, Female, Unshielded, IDC Termination, Cable Diameter 4.00-8.00mm

Documents:

[Drawing \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)

General

Product Family	Field Attachable / Accessories
Series	120071
Approvals	cRUus - UL Recognized
IP Rating	IP67
Material - Contact	Copper Alloy
Overview	Brad Micro-Change (M12) Connectors
Product Name	Micro-Change (M12)
Type	Field Attachable Connector
UPC	889056509954

Physical

Cable Diameter	4.00-8.00mm (.157-.315")
Coupling Type	Internal Thread
Diagnostics / LEDs	No
Diagnostics Port	No
Gender	Female
Keyway	Single
Material - Connector Body	PA
Material - Coupling Nut	Zinc Die-Cast, Nickel-Plated
Material - Plating Mating	Gold
Net Weight	14.000/g
Orientation	Straight
Poles	4
Temperature Range - Operating	-25°C to +80°C
Wire Size AWG	18-22

Electrical


Current - Maximum per Contact	4.0A
Voltage - Maximum	250V

Material Info

Engineering Number	8A4000-52
--------------------	-----------

Reference - Drawing Numbers

Sales Drawing	1200710089-000
---------------	----------------

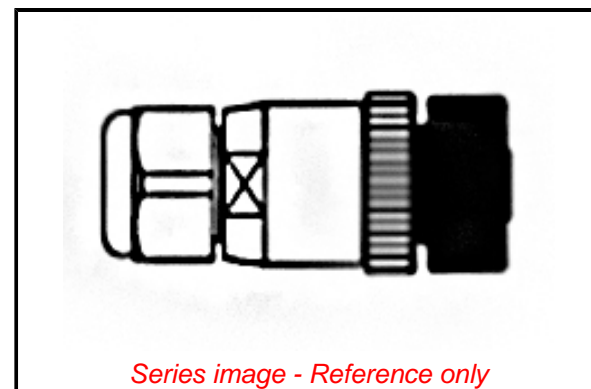

EU ELV

Not Relevant

EU RoHS

Compliant
REACH SVHC

Not Reviewed

Halogen-Free

Status

Not Reviewed

For more information, please visit [Contact US](#)

China ROHS

ELV

RoHS Phthalates

China RoHS

Green Image

Not Relevant

Not Contained

Search Parts in this Series

[120071](#) Series

Mates With

[1200710088](#)