


4-174821-4 Product Details

Have a Question?

Chat with a Product Information Specialist

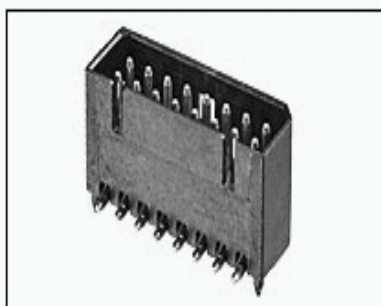

4-174821-4

1.25mm Centerline F-P (Fine Pitch Connectors)

[Converted to EU RoHS/ELV Compliant \(Statement of Compliance\)](#)

Product Highlights:

- Header
- Connector Style = Plug
- PCB Mount Style = Surface Mount
- Vertical Mount Angle
- Number of Rows = Dual

[View all Features](#)

TE Internal Number: 4-174821-4

Active

[View 3D PDF](#)

[Add to My Part List](#) [Request Sample](#) [Find Similar Products](#) [Buy Product](#)

Quick Links

- ▶ [Check Pricing & Availability](#)
- ▶ [Search for Tooling](#)
- ▶ [Product Feature Selector](#)
- ▶ [Contact Us About This Product](#)

Documentation & Additional Information

Product Drawings:

- [1.25 F-P CONNECTOR \(B-TO-B\) DOUBLE ROW POST HDR ASS'...](#) (PDF, Japanese)

Catalog Pages/Data Sheets:

- None Available

Product Specifications:

- [AMP 1.25mm F-P Connector \(Board To Board\)](#) (PDF, Japanese)

Application Specifications:

- None Available

Instruction Sheets:

- None Available

CAD Files: ([CAD Format & Compression Information](#))

- [2D Drawing](#) (DXF, Version N)
- [3D Model](#) (IGES, Version N)
- [3D Model](#) (STEP, Version N)

[List all Documents](#)

Additional Information:

- [Product Line Information](#)

Related Products:

- [Tooling](#)

Product Features (Please use the Product Drawing for all design activity)

Product Type Features:

- Connector Type = Header
- [PCB Mount Style](#) = Surface Mount
- [Mount Angle](#) = Vertical
- [PCB Mount Retention](#) = With
- [Polarization](#) = With

Body Related Features:

- [Number of Rows](#) = Dual
- [Number of Positions](#) = 14
- [PCB Mount Retention Type](#) = Hold Down Post(s)
- Polarization Method = Long Rib
- Centerline (mm [in]) = 1.25 [0.049]
- Housing Height (mm [in]) = 3.95 [0.156]

Contact Related Features:

- [Contact Plating, Mating Area, Material](#) = Pre-Tin
- Contact Base Material = Brass

Housing Related Features:

- Connector Style = Plug
- Housing Material = PPS
- Housing Color = Black
- UL Flammability Rating = UL 94V-0

Industry Standards:

- [RoHS/ELV Compliance](#) = RoHS compliant, ELV compliant
- [Lead Free Solder Processes](#) = Reflow solder capable to 245°C
- RoHS/ELV Compliance History = Converted to comply with RoHS directive

Packaging Related Features:

- [Packaging Method](#) = Loose Piece

Other:

- Brand = AMP

BOOKMARK

Corporate Information

- [Who We Are](#)
- [Investors](#)
- [News Room](#)
- [Supplier Portal](#)
- [Careers](#)

Quick Links

- [Check Distributor Inventory](#)
- [Cross Reference](#)
- [Find Documents & Drawings](#)
- [Product Compliance Support Center](#)
- [Site Map](#)

 
Customer Support

- [Email or Chat with Us](#)
- [Find a Phone Number](#)
- [Search Knowledge Base](#)
- [Manage Your Account](#)

Sign up for our eNewsletter

Enter your email address

Follow Us On:



Visit Us On:

