


## ARF0810K Product Details

[Live Product Chat](#)

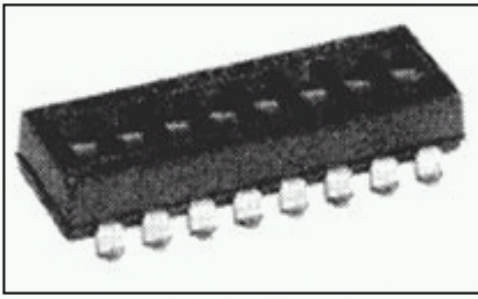

**ARF0810K**

TE Part Number: 1-1437588-8

[Superseded](#)

[Add to Part List](#)  
[Search for Replacement Parts](#)

### DIP, Rotary DIP, SIP Switches and DIP Shunts - Standard

[Not EU RoHS or ELV Compliant \(Find RoHS Compliant Alternates\)](#)

#### Product Highlights:

- DIP Switch
- PCB Mount Style = Thru Hole
- Single Pole - Single Throw Configuration (Pole-Throw)
- Actuator Style = Flush
- Not Sealed

[View all Features](#) | [Find Similar Products](#)

### Quick Links

- ▶ [Check Pricing & Availability](#)
- ▶ [Search for Tooling](#)
- ▶ [Product Feature Selector](#)
- ▶ [Contact Us About This Product](#)
- ▶ [Request Samples](#)

**NEW!**

### Documentation & Additional Information

#### Product Drawings:

- None Available

#### Catalog Pages/Data Sheets:

- None Available

#### Product Specifications:

- None Available

#### Application Specifications:

- None Available

#### Instruction Sheets:

- None Available

#### CAD Files:

- None Available

#### Additional Information:

- [Product Line Information](#)

#### Related Products:

- [Tooling](#)

### Product Features (Please use the Product Drawing for all design activity)

#### Product Type Features:

- Product Type = DIP Switch
- PCB Mount Style = Thru Hole
- [Configuration \(Pole-Throw\)](#) = Single Pole - Single Throw
- [Actuator Style](#) = Flush
- Sealed = No
- [Number of Switches](#) = 8

#### Electrical Characteristics:

- Resistor Specification ( $\Omega$ ) = 10,000

#### Body Related Features:

- Series = AR
- Centerline (mm [in]) = 2.54 [0.100]

#### Contact Related Features:

- Auto-Insertable = Yes

#### Housing Related Features:

- Low Profile = Yes
- Housing Material = Polyester
- Housing Flammability Rating = UL 94V-0

#### Industry Standards:

- [RoHS/ELV Compliance](#) = Not ELV/RoHS compliant
- [Lead Free Solder Processes](#) = Wave solder capable to 240°C

#### Other:

- Brand = Alcoswitch

[Provide Website Feedback](#) | [Need Help?](#)