


## 1123364-1 Product Details


 [Share](#)
 [Print](#)
 [Email](#)

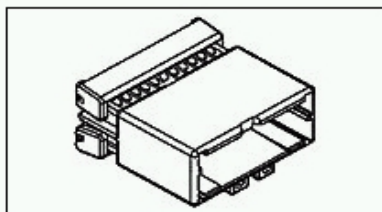

1123364-1

TE Internal Number: 1123364-1

 **Active**

 [View 3D PDF](#)

### MULTILOCK Connectors and Contacts

 [Always EU RoHS/ELV Compliant \(Statement of Compliance\)](#)

#### Product Highlights:

- Connector
- Housing
- Contact Type = Tab
- Connector Style = Receptacle
- Receptacle Configuration = 040

[View all Features](#)

### Quick Links

- [Check Pricing & Availability](#)
- [Search for Tooling](#)
- [Product Feature Selector](#)
- [Contact Us About This Product](#)

 [Add to My Part List](#)
 [Request Sample](#)
 [Find Similar Products](#)
 [Buy Product](#)

### Documentation & Additional Information

#### Product Drawings:

- [040 III MULTILOCK CONNECTOR 24POSITION CAP HOUSING A...](#) (PDF, English)

#### Catalog Pages/Data Sheets:

- None Available

#### Product Specifications:

- [.040 III Series Multilock Connector \(MLC\) for Wi... \(1\)](#) (PDF, Japanese)
- [.040 III Series Multilock Connector \(MLC\) for Wi... \(2\)](#) (PDF, Japanese)

#### Application Specifications:

- [Crimping .040III Unsealed Contact, Tab](#) (PDF, Japanese)

#### Instruction Sheets:

- None Available

#### CAD Files: ([CAD Format & Compression Information](#))

- [2D Drawing](#) (DXF, Version C)
- [3D Model](#) (IGES, Version C)
- [3D Model](#) (STEP, Version C)

[List all Documents](#)

#### Additional Information:

- [Product Line Information](#)

#### Related Products:

- [Tooling](#)

### Product Features (Please use the Product Drawing for all design activity)

#### Product Type Features:

- [Product Type](#) = Connector
- [Connector Type](#) = Housing
- [Receptacle Configuration](#) = 040
- [Wire/Cable Type](#) = Discrete Wire
- [Mating Connector Lock](#) = With
- [Mating Connector Number Positions](#) = 24
- [Keyed](#) = No
- [Proprietary Name](#) = MULTILOCK
- [Product Series](#) = 040 III

#### Mechanical Attachment:

- [Panel Mount Retention](#) = Without

#### Body Features:

- [Number of Rows](#) = 2
- [Number of Positions](#) = 24

#### Contact Features:

- [Contact Type](#) = Tab

#### Housing Features:

- [Connector Style](#) = Receptacle
- [Housing Color](#) = Natural
- [Housing Material](#) = PBT - GF

#### Industry Standards:

- [RoHS/ELV Compliance](#) = RoHS compliant, ELV compliant
- [Lead Free Solder Processes](#) = Not relevant for lead free process
- [RoHS/ELV Compliance History](#) = Always was RoHS compliant

#### Conditions for Usage:

- [Applies To](#) = Wire/Cable

#### Other:

- [Brand](#) = AMP

### Corporate Information

[Who We Are](#)  
[Investors](#)  
[News Room](#)  
[Supplier Portal](#)  
[Careers](#)

### Quick Links

[Check Distributor Inventory](#)  
[Cross Reference](#)  
[Find Documents & Drawings](#)  
[Product Compliance Support Center](#)  
[Site Map](#)

### Customer Support

[Email or Chat With Us](#)  
[Find a Phone Number](#)  
[Search Knowledge Base](#)  
[Manage your Account](#)

### Keep Me Informed

Receive TE News, Events & Technology Updates

Enter your email address

