





**Modular Jacks** (Continued)

**RJ45 Single Port** (Continued)


**Side Entry, Shielded, Through-hole, 10mm Height**

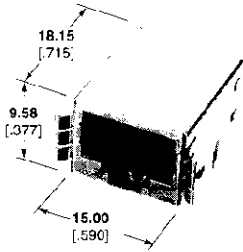

(Photo 109264-7)

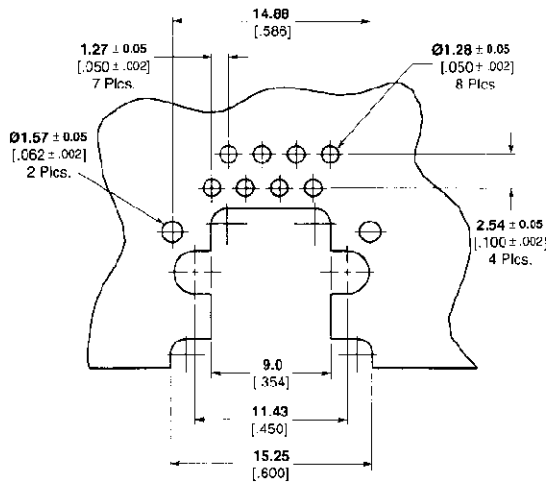

**Recommended PC Board Layout**

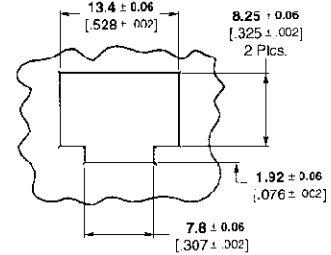


**Recommended Panel Cutout**


Pos./Contacts	(IR) Reflow Compatible	Panel Ground	Part Number	Performance Level
8/8	Y	Y	1116062-1	CAT 5 (2 Pair 1-2 3-6)
8/8	Y	N	1116503-1	CAT 5 (2 Pair 1-2 3-6)
8/8	Y	N	1116504-1	CAT 5 (2 Pair 1-2 3-6) (unshielded)

**Note:** Shielded product with panel grounds always contains PCB grounds.


**Top Entry, Unshielded, Through-hole**

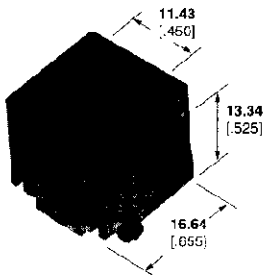

(Photo 109864-3)

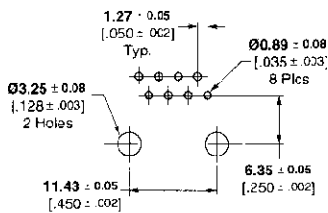

**Recommended PC Board Layout**

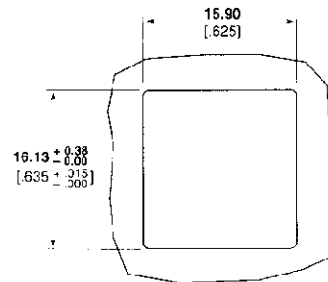

**Recommended Panel Cutout**

Pos./Contacts	(IR) Reflow Compatible	Panel Stops	Part Number	Keyed	Performance Level
8/8	—	Y	520259-4	—	CAT 3
8/8	Y	—	569234-1	—	CAT 3
8/8	—	—	556416-1	—	CAT 3
8/8	—	Y	520260-4	Y	CAT 3
8/8	—	—	555799-1	Y	CAT 3