


COIL: @ 25°C	
RESISTANCE	330 OHMS ± 10%
NOMINAL VOLTAGE	26.5 VDC
MUST OPERATE	13.0 VDC
MUST RELEASE	2.0 VDC MIN.

CUSTOMER DATA SHEET

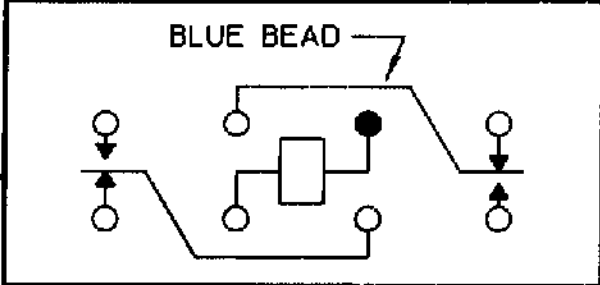

ENVIRONMENT:

VIBRATION	10	CPS TO	2000	CPS @	20	g's
SHOCK	100	g's	6	MS. DURATION		
TEMPERATURE	-65	°C TO	+125	°C		

CONTACT RATING:	10 AMPS 30 VDC RES.
	10 AMPS 115 VAC 400 Hz. 6A 30 VDC
	INDUCTIVE 100,000 OPERATIONS

NOTES:

OPERATE TIME	13 MS MAX.
RELEASE TIME	5 MS MAX.
CONTACT BOUNCE	5 MS MAX. (NC)
	2 MS MAX. (NO)

DR. R.E. 1/12/95 CK. 1/12/95

COMMUNICATIONS INSTRUMENTS, INC.

CUST. HI-G

CUST. NO. 2T-1B-126

TYPE '07' RELAY

B07B932BZ1-8005