

**COIL:**


RESISTANCE 675 Ω ± 10%  
 NOMINAL VOLTAGE 26.5 VDC  
 MUST OPERATE 13.5 VDC  
 MUST RELEASE 2.3 VDC

**ENVIRONMENT:**

VIBRATION 10 CPS TO 2000 CPS @ 20 g's  
 SHOCK 100 g's 6 MS.DURATION  
 TEMPERATURE -65° °C TO +125° °C

**NOTES:**

**CUSTOMER DATA SHEET**

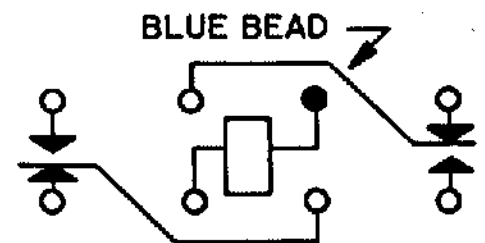

CONTACT RATING: 2A 28 VDC  
 RESISTIVE 100,000 OPERATIONS

DR. R.B. 1-18-90 CK. 1/8/90



CUST. QPL  
 CUST. NO. M5757/10-015

TYPE "FW" RELAY

**FW1167G03**