


REV. 1  
DCO 16356

|                 |                             |
|-----------------|-----------------------------|
| COIL: @ 25°C    | 540 - 770 OHMS              |
| RESISTANCE      |                             |
| NOMINAL VOLTAGE | 26.5 VDC                    |
| MUST OPERATE    | 13.0 VDC                    |
| MUST RELEASE    | 10.1 VDC MAX., 2.3 VDC MIN. |

|              |                             |
|--------------|-----------------------------|
| ENVIRONMENT: |                             |
| VIBRATION    | 10 CPS TO 2000 CPS @ 15 g's |
| SHOCK        | 100 g's 6 ± 1 MS. DURATION  |
| TEMPERATURE  | -65 °C TO +125 °C           |

NOTES: OPERATE & RELEASE 6 MS MAX.  
CONTACT BOUNCE 1 MS MAX.

### CUSTOMER DATA SHEET

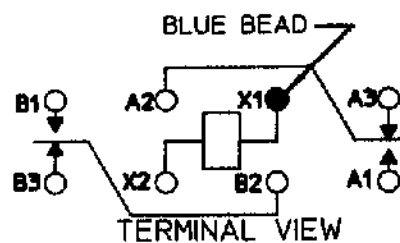

CONTACT RATING: 2A 28 VDC RESISTIVE 100,000 OPERATIONS MINIMUM

DR. PBB 5-5-00

CK. TLG 7-12-00

COMMUNICATIONS  
INSTRUMENTS, INC.

CUST. QPL  
CUST. NO. M5757/10-054 REV.

'FW' RELAY

FW1201G03