

REV. 0  
DCO 16835


COIL: @ 25°C	
RESISTANCE	27 OHMS ±10%
NOMINAL VOLTAGE	5.0 VDC
MUST OPERATE	2.7 VDC
MUST RELEASE	.29 VDC

ENVIRONMENT:

VIBRATION	10	CPS TO	2000	CPS @	20	g's
SHOCK	100	g's	6	MS. DURATION		
TEMPERATURE	-55	°C TO	+85	°C		

NOTES: OPERATE & RELEASE 4 MS MAX  
CONTACT BOUNCE 2 MS MAX

CUSTOMER DATA SHEET

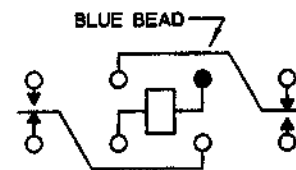

TERMINAL VIEW

CONTACT RATING: LOW LEVEL TO 5 A  
28 VDC RESISTIVE 100,000 OPERATIONS

DR. PBB 2/22/01 | CK. TLG 02-22-01



CUST. CII STD  
CUST. NO. \_\_\_\_\_ REV. \_\_\_\_\_ HFW5A RELAY

HFW5A1230L00