


## D-436-0097 Product Details

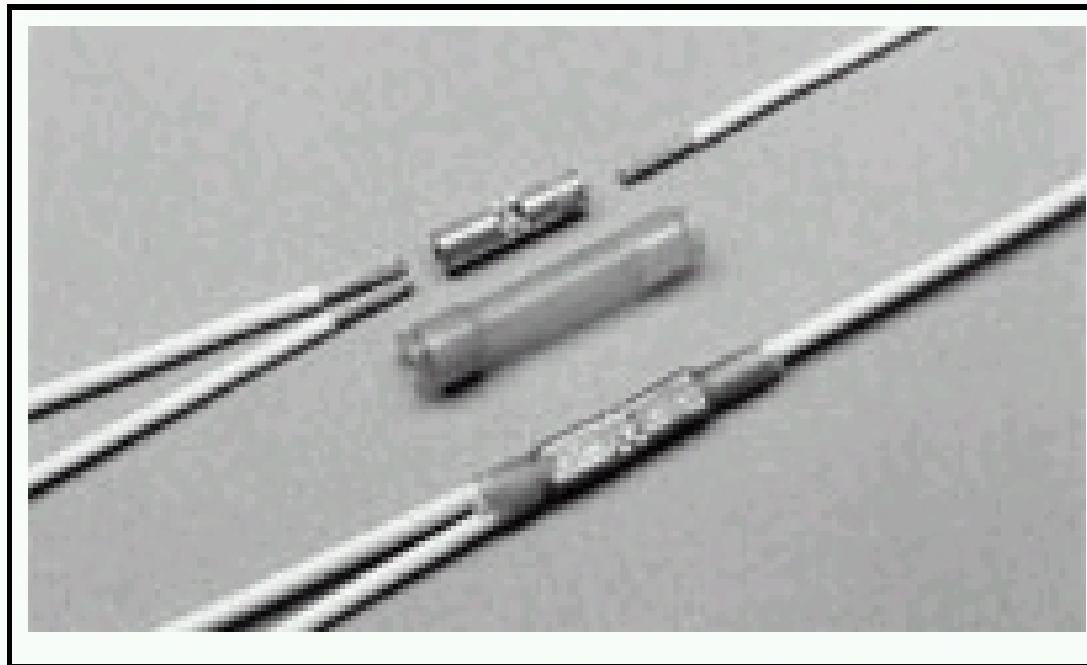

### D-436-0097

TE Part Number: 650137-000

 [Active](#)

 [Add to Part List](#)

## Shield Terminators

 [Always EU RoHS/ELV Compliant \(Statement of Compliance\)](#)

### Product Highlights:

- Sealing = Immersion Resistant
- Cable Temperature Rating = 135 °C
- Jacket Outer Diameter = .63 - 2.80 mm
- Without Preinstalled Lead
- Without Temperature Indication System

[View all Features](#) | [Find Similar Products](#)

## Quick Links

- ▶ [Check Pricing & Availability](#)
- ▶ [Search for Tooling](#)
- ▶ [Product Feature Selector](#)
- ▶ [Contact Us About This Product](#)

## Documentation & Additional Information

### Product Drawings:

- [Sealing Sleeve](#) (PDF, English)

### Catalog Pages/Data Sheets:

- None Available

### Product Specifications:

- None Available

### Application Specifications:

- None Available

### Instruction Sheets:

- None Available

### CAD Files:

- None Available

### Additional Information:

- [Product Line Information](#)

### Related Products:

- [Tooling](#)

[List all Documents](#)

## Product Features (Please use the Product Drawing for all design activity)

### Mechanical Attachment:

- Inside Diameter (mm [in]) = 2.80 [0.110]

### Body Related Features:

- [Jacket Outer Diameter \(mm \[in\]\)](#) = 0.63 - 2.80 [0.025 - 0.110]

### Housing Related Features:

- [Sealing](#) = Immersion Resistant
- [Preinstalled Lead](#) = Without
- MIL or NAS Specification (MIL-S-83519) (NAS 1747) = No
- Length (Max.) (mm [in]) = 29.30 [1.150]

### Configuration Related Features:

- Temperature Indication System = Without

### Industry Standards:

- [RoHS/ELV Compliance](#) = RoHS compliant, ELV compliant
- [Lead Free Solder Processes](#) = Not relevant for lead free process
- RoHS/ELV Compliance History = Always was RoHS compliant

### Conditions for Usage:

- [Cable Temperature Rating \(°C\)](#) = 135
- Operating Temperature (Max.) (°C) = 150

### Other:

- Brand = Raychem