



TE CONNECTIVITY (TE)
JC6-Q308-13=JC6 ASSY

Buchanan | [JC6 Series](#)

1-1546700-2
 TE Internal Number: 1-1546700-2
 Alias ID: JC6-Q308-13

[EU RoHS Compliant](#)
[EU ELV Compliant](#)

Barrier Style **Dual Barrier**

Bottom Termination Style **Quick Connects**

Current Rating (A) **20**

Number of Positions **13**

Centerline (Pitch) **9.53 mm [.375 in]**
[See All Features](#)

✓ Active

↓ **PRODUCT DRAWING**
 English

↓ **3D PDF**

> [See All Documentation](#)

North America ▼

DISTRIBUTOR	QUANTITY	DATE AS OF
MASTER ELECTRONICS CORP. 1-888-473-5297	77	2017/09/26

GET SAMPLE	
SAVE TO LIST ▼	
CHECK FOR TOOLING	
FIND SIMILAR PRODUCTS	

DOCUMENTATION

FEATURES

PRODUCT COMPLIANCE

Product Drawings

[JC6-Q308-XX ASSEMBLY](#)
 PDF
English

CAD Files

[Customer View Model](#)
 2D_DXF.ZIP
English

[3D PDF](#)
 PDF
3D

[Customer View Model](#)
 3D_IGS.ZIP
English

[Customer View Model](#)
 3D_STP.ZIP

Please review product documents or [contact us](#) for the latest agency approval information. Please Note: Use the Product Drawing for all design activity.

Product Type Features

Block Style **Turret (Insulated)**Product Type **Barrier Strip**

Configuration Features

Number of Positions **13**Number of Rows **1**Number of Levels **1**

Electrical Characteristics

Current Rating (A) **20**Voltage (V) **300**

Body Features

Barrier Style **Dual Barrier**Color **Black**

Contact Features

Terminal Plating Finish **Bright**Terminal Material **Copper Alloy**Terminal Plating Material **Tin**

Termination Features

Bottom Termination Style **Quick Connects**

Mechanical Attachment

Connector Mounting Type **Panel**Screw Size **6-32**Mounting Ears **With**Mounting Options **End Mounting Ears**Screw Material **Steel**Screw Plating Material **Zinc Chromate**Top Hardware **Wire Clamp Combo Head**

Mounting Insert **Without**

Screw Head Type **Wire Clamp Combo Head**

Mounting Angle **Vertical**

Housing Features

Centerline (Pitch) **9.53 mm [.375 in]**

Housing Material **Thermoplastic**

Dimensions

Wire Range **22 – 12AWG [.3 – 3 mm²]**

Length **141.326 mm [5.564 in]**

Industry Standards

UL Flammability Rating **UL 94V-0**

Packaging Features

Packaging Method **Package**

Packaging Quantity **40**

Other

Comment **Other options available upon request, consult our Product Information Center.**


Statement of Compliance

[Statement of Compliance](#)
PDF

Compatible Products

[Contact Product Support](#)

Also in the Series | [JC6 Series](#)

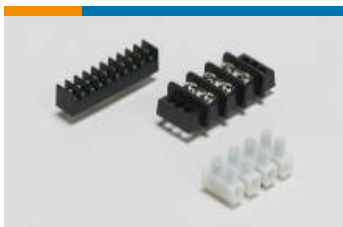

[Barrier Strips \(2135\)](#)

Customers Also Bought

[BARRIER STRIPS](#)

[SINGLE PHASE FILTERS](#)

[POWER RELAYS](#)

[POWER RELAYS](#)



.250QC, 90 DEG, DBL,
SSB7, LONG
1776090-2



6VV1=F7251 S0
6VV1



KUP-11D15-24=KU
KUP-11D15-24



KUP-14A45-120=KU
KUP-14A45-120

About TE Connectivity

For Partners

Customer Support

CALL US

LIVE CHAT

United States

Our Company

Events

TE News Center

Careers

Investors

Corporate Responsibility

Terms and Conditions of
Sale

Distributors

Suppliers

✉ Email or Call Us

🔍 Find Authorized Distributors

✓ What's New on TE.com

? Product FAQs

Select Country & Language

United States (EN)

Germany (DE)

China (中文)

Japan (日本語)

Afghanistan (EN) ▼

Find Your Country ▼

Terms of Use | Privacy | Cookie Policy | Accessibility | Site Map



© 2017 TE Connectivity Corporation. All Rights Reserved