


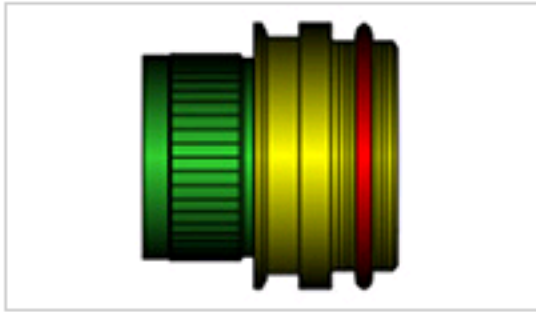

STXR41AB00-1212AI Product Details

[Share](#) | [Print](#) | [Email](#)


Braid, Fixed, Spin and Tinel Lock Adapters

STXR41AB00-1212AI
STXR41AB00-1212AI
 TE Internal Number: 801005-000

Active

[View 3D PDF](#)

Product Highlights [View All](#)

- Applies To Cable
- Military Style Number = MIL-C-38999
- Style = Tinel Lock
- Connector Code = 41
- Straight

[Pricing & Availability](#)

[Request Sample](#)

[Add to My Part List](#)

[Buy Product through Distributor](#)

Feedback

[Documents](#) | [Features](#) | [Compliance](#)

Please Note:
 Use the Product Drawing for all design activity

Product Type Features	
Style ?	Tinel Lock
Angle ?	Straight
Connector Shell Size	12
Finish	Cadmium Plating over Electroless Nickel
Color	Olive Drab

Dimensions	
Boot Diameter (mm [in]) ?	26.27 [1.034]
Cable Diameter Range (mm [in])	11.00 - 18.20 [0.430 - 0.720]

Body Features	
Connector Code ?	41
Entry Size	12
Material	Aluminum Alloy

Industry Standards	
Government/Industry Qualification	No
Military Style Number	MIL-C-38999
RoHS/ELV Compliance ?	Not ELV/RoHS compliant
Lead Free Solder Processes ?	Not relevant for lead free process

Conditions for Usage	
Applies To	Cable

Other	
Brand	Raychem
Comment	For Specific shell size information, refer to Harnware™ or Catalogue.

Related Products

Not quite the product you're looking for?
[Find Similar Products](#)

[View Part in Product Feature Selector](#)

[Check for Tooling](#)

Corporate Information

- [About TE](#)
- [Investors](#)
- [News Room](#)
- [Supplier Portal](#)
- [Careers](#)
- [Terms & Conditions](#)
- [Privacy Policy](#)
- [Global Accessibility Statement](#)

Quick Links

- [Distributor Inventory](#)
- [Product Cross Reference](#)
- [Documents & Drawings](#)
- [Product Compliance Support Center](#)
- [Site Map](#)

Customer Support

- [Email or Chat With Us](#)
- [Find a Phone Number](#)
- [Knowledge Base](#)
- [Manage Your Account](#)

Keep Me Informed

