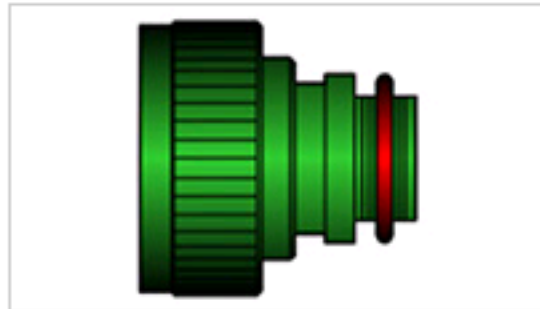


# TXR40AZ00-1804BI Product Details

[Share](#) | [Print](#) | [Email](#)


✓ Active

## Braid, Fixed, Spin and Tinel Lock Adapters

TXR40AZ00-1804BI  
**TXR40AZ00-1804BI**  
 TE Internal Number: CW4644-000

**Product Highlights** [View All](#)

- Applies To Cable
- Military Style Number = MIL-DTL-38999
- Style = Tinel Lock
- Connector Code = 40
- Straight

- [Pricing & Availability](#)
- [Request Sample](#)
- [Add to My Part List](#)
- [Buy Product through Distributor](#)

Feedback

[Documents](#) | [Features](#) | [Compliance](#)

**Please Note:**  
 Use the Product Drawing for all design activity

Product Type Features	
Style ?	Tinel Lock
Angle ?	Straight
Connector Shell Size	18
Finish	Zinc Nickel
Color	Black

Dimensions	
Boot Diameter (mm [in]) ?	13.97 [0.550]
Cable Diameter Range (mm [in])	3.50 - 5.50 [0.140 - 0.220]

Body Features	
Connector Code ?	40
Entry Size	4
Material	Aluminum Alloy

Configuration Features	
Braid ?	Double 36 AWG Braid

Industry Standards	
Government/Industry Qualification	No
Military Style Number	MIL-DTL-38999
RoHS/ELV Compliance ?	Not ELV/RoHS compliant
Lead Free Solder Processes ?	Not relevant for lead free process

Conditions for Usage	
Applies To	Cable

Other	
Brand	Raychem
Comment	For specific shell size information, refer to "Hardware" or Catalog.

**Related Products**

Not quite the product you're looking for?  
[Find Similar Products](#)

[View Part in Product Feature Selector](#)

[Check for Tooling](#)