


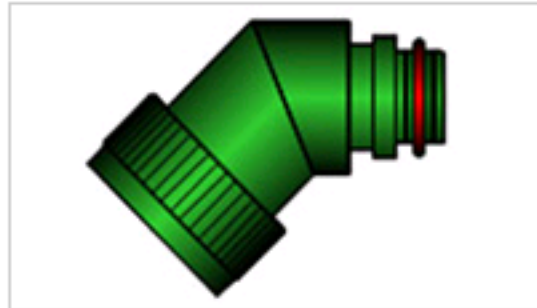

TXR41AB45-1006BI Product Details

[Share](#) | [Print](#) | [Email](#)


✓ Active

Braid, Fixed, Spin and Tinel Lock Adapters

TXR41AB45-1006BI

TXR41AB45-1006BI

TE Internal Number: 064111-000

Product Highlights [View All](#)

- Applies To Cable
- Military Style Number = MIL-C-38999
- Style = Tinel Lock
- Connector Code = 41
- 45°

[Pricing & Availability](#)

[Request Sample](#)

[Add to My Part List](#)

[Buy Product through Distributor](#)

Feedback

[Documents](#)

[Features](#)

[Compliance](#)

Please Note:

Use the Product Drawing for all design activity

Product Type Features

Style [?]	Tinel Lock
Angle [?]	45°
Connector Shell Size	10
Finish	Cadmium Plating over Electroless Nickel
Color	Olive Drab

Dimensions

Boot Diameter (mm [in]) [?]	17.14 [0.675] ▼
Cable Diameter Range (mm [in])	4.50 - 8.70 [0.180 - 0.340]

Body Features

Connector Code [?]	41
Entry Size	6
Material	Aluminum Alloy

Configuration Features

Braid [?]	Double 36 AWG Braid, Single 30 AWG Braid
Industry Standards	
Government/Industry Qualification	No
Military Style Number	MIL-C-38999
RoHS/ELV Compliance [?]	Not ELV/RoHS compliant
Lead Free Solder Processes [?]	Not relevant for lead free process ▼

Conditions for Usage

Applies To	Cable
------------	-------

Other

Brand	Raychem
Comment	For Specific shell size information, refer to Harnware™ or Catalogue.

Related Products

Not quite the product you're looking for?

[Find Similar Products](#)

[View Part in Product Feature Selector](#)

[Check for Tooling](#)

Corporate Information

- [About TE](#)
- [Investors](#)
- [News Room](#)
- [Supplier Portal](#)
- [Careers](#)
- [Terms & Conditions](#)
- [Privacy Policy](#)
- [Global Accessibility Statement](#)

Quick Links

- [Distributor Inventory](#)
- [Product Cross Reference](#)
- [Documents & Drawings](#)
- [Product Compliance Support Center](#)
- [Site Map](#)

Customer Support

- [Email or Chat With Us](#)
- [Find a Phone Number](#)
- [Knowledge Base](#)
- [Manage Your Account](#)

Keep Me Informed

