




**NECTOR | NECTOR S**

TE Internal #: 293388-3

Plug & Socket Lighting Connectors, Cable-to-Cable, 2 Position, Wire & Cable, Plug, 125 VAC, Power, Cable Mount (Free-Hanging), NECTOR S

[View on TE.com >](#)

Connectors > Lighting Connectors > Plug & Socket Connectors

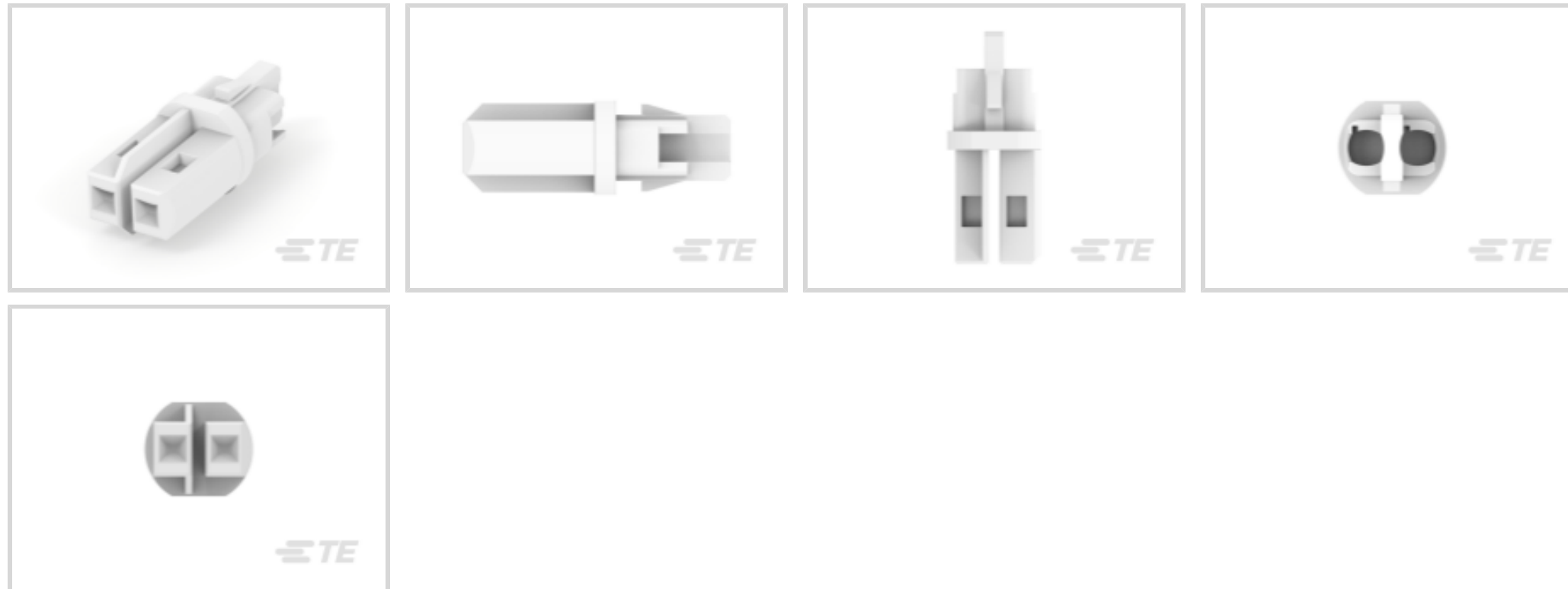

Connector System: **Cable-to-Cable**

Number of Positions: **2**

Sealable: **No**

Connector & Contact Terminates To: **Wire & Cable**

Lighting Connector Style: **Plug**

**Features**

**Product Type Features**

Product Type	Connector
Wire/Cable Type	Discrete Wire
Connector System	Cable-to-Cable
Sealable	No
Connector & Contact Terminates To	Wire & Cable
Lighting Connector Style	Plug

**Configuration Features**

Keying Arrangement	HV-4
Number of Positions	2
Contacts Preloaded	No

**Electrical Characteristics**

Operating Voltage	125 VAC
-------------------	---------

**Contact Features**

Accepts Contact Style	Socket
-----------------------	--------



Contact Type	Socket
--------------	--------

### Mechanical Attachment

Connector Mounting Type	Cable Mount (Free-Hanging)
-------------------------	----------------------------

### Housing Features

Housing Color	White
---------------	-------

### Operation/Application

Circuit Application	Power
---------------------	-------

### Industry Standards

VDE Tested	No
------------	----

### Packaging Features

Packaging Method	Bag
------------------	-----

## Product Compliance

[For compliance documentation, visit the product page on TE.com>](#)

EU RoHS Directive 2011/65/EU	Compliant
------------------------------	-----------

EU ELV Directive 2000/53/EC	Compliant
-----------------------------	-----------

China RoHS 2 Directive MIIT Order No 32, 2016	No Restricted Materials Above Threshold
---	---

EU REACH Regulation (EC) No. 1907/2006	Current ECHA Candidate List: JUNE 2022 (224) Candidate List Declared Against: JUNE 2022 (224) Does not contain REACH SVHC
--	---

Halogen Content	Not Low Halogen - contains Br or Cl > 900 ppm.
-----------------	--

Solder Process Capability	Not reviewed for solder process capability
---------------------------	--

#### Product Compliance Disclaimer

This information is provided based on reasonable inquiry of our suppliers and represents our current actual knowledge based on the information they provided. This information is subject to change. The part numbers that TE has identified as EU RoHS compliant have a maximum concentration of 0.1% by weight in homogenous materials for lead, hexavalent chromium, mercury, PBB, PBDE, DBP, BBP, DEHP, DIBP, and 0.01% for cadmium, or qualify for an exemption to these limits as defined in the Annexes of Directive 2011/65/EU (RoHS2). Finished electrical and electronic equipment products will be CE marked as required by Directive 2011/65/EU. Components may not be CE marked. Additionally, the part numbers that TE has identified as EU ELV compliant have a maximum concentration of 0.1% by weight in homogenous materials for lead, hexavalent chromium, and mercury, and 0.01% for cadmium, or qualify for an exemption to these limits as defined in the Annexes of Directive 2000/53/EC (ELV). Regarding the REACH Regulation, the information TE provides on SVHC in articles for this part number is based on the latest European Chemicals Agency (ECHA) 'Guidance on requirements for substances in articles' posted at this URL: <https://echa.europa.eu/guidance-documents/guidance-on-reach>

## Compatible Parts



TE Part # 293653-3  
NECTOR S PCB CONN. ASSY. STRAIGHT PLUG



TE Part # 293359-1  
NECTOR S TUBE FOR SVT CABLE



TE Part # 293388-5  
NECTOR S PLUG LV-2 WHITE



TE Part # 293388-2  
NECTOR S PLUG HV-3 WHITE



TE Part # 293650-1  
NECTOR S T-SPLITTER STANDARD HV-4 WHITE



TE Part # 293652-3  
NECTOR S PCB CONN. ASSY. 90 DEG OUTLET



TE Part # 293390-1  
MICRO QUADLOK SYSTEM SOCKET CONTACT

TE Part # 1-2213222-5  
NECTOR S BUS BAR SEALED US, THRU HV-4

TE Part # 2-2213222-5  
NECTOR S BUS BAR SEALED US END, TAB HV-4

TE Part # 2213222-5  
NECTOR S BUS BAR SEALED US THRU TAB HV-4

TE Part # 293649-3  
NECTOR S T-SPLITTER SWITCH VERSION HV4

TE Part # 3-2213222-5  
NECTOR S BUS BAR SEALED US, END HV-4


TE Part # 4-2213222-5  
NECTOR S BUS BAR US THRU TAB HV-4

TE Part # 5-2213222-5  
NECTOR S BUS BAR US, THRU HV-4


TE Part # 6-2213222-5  
NECTOR S BUS BAR US END, TAB HV-4

TE Part # 7-2213222-5  
NECTOR S BUS BAR US, END HV-4

## Also in the Series | NECTOR S




Insertion & Extraction Tools(3)



Lighting Cable Assemblies(1)



Plug & Socket Lighting Connector Accessories(57)



Plug & Socket Lighting Connectors(54)



## Documents

### Product Drawings

#### NECTOR S PLUG HV-4 WHITE

English

---

### CAD Files

#### 3D PDF

3D

#### Customer View Model

[ENG\\_CVM\\_CVM\\_293388-3\\_C.2d\\_dxf.zip](#)

English

#### Customer View Model

[ENG\\_CVM\\_CVM\\_293388-3\\_C.3d\\_igs.zip](#)

English

#### Customer View Model

[ENG\\_CVM\\_CVM\\_293388-3\\_C.3d\\_stp.zip](#)

English

By downloading the CAD file I accept and agree to the [Terms and Conditions](#) of use.

---

### Datasheets & Catalog Pages

#### NECTOR\_S\_LINE\_CONNECTOR\_BROCHURE

English

---

### Product Specifications

#### Application Specification

English

---

### Agency Approvals

#### UL Report

English