

59461 ✓ ACTIVE

AMP


TE Internal #: 59461

Hand Crimping Tools, Premium Crimp Tooling, Not Releasable,  
Not Adjustable, Fixed In Tool, MIL Spec / TE Product Specification  
(114-)

[View on TE.com >](#)



Application Tooling > Hand Crimping Tools

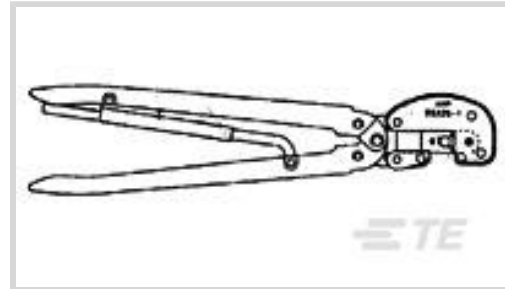

Tool Grade: **Premium Crimp Tooling**

Ratchet Configuration: **Not Releasable, Not Adjustable**

Die Sets Type: **Fixed In Tool**

Specification Type: **MIL Spec, TE Product Specification (114-)**

TE Certification: **Yes – Certificate Included**

## Features

### Other

Crimp Form-Wire Barrel Type	Closed Barrel - Confined Crescent
Tool Grade	Premium Crimp Tooling
Ratchet Configuration	Not Releasable, Not Adjustable
Die Sets Type	Fixed In Tool
Specification Type	MIL Spec, TE Product Specification (114-)
TE Certification	Yes – Certificate Included
Power Technology Type	Battery, Manual
Tooling Type	Heavy Head Hand Tool

## Product Compliance

[For compliance documentation, visit the product page on TE.com>](#)

EU RoHS Directive 2011/65/EU	Out of Scope
EU ELV Directive 2000/53/EC	Out of Scope
China RoHS 2 Directive MIIT Order No 32, 2016	Not reviewed for China RoHS compliance
EU REACH Regulation (EC) No. 1907/2006	Current ECHA Candidate List: JUNE 2022 (224) Candidate List Declared Against: JUL 2021 (219) Does not contain REACH SVHC
Halogen Content	Low Halogen - Br, Cl, F, I < 900 ppm per



homogenous material. Also BFR/CFR/PVC Free

Solder Process Capability

Not applicable for solder process capability

Product Compliance Disclaimer

This information is provided based on reasonable inquiry of our suppliers and represents our current actual knowledge based on the information they provided. This information is subject to change. The part numbers that TE has identified as EU RoHS compliant have a maximum concentration of 0.1% by weight in homogenous materials for lead, hexavalent chromium, mercury, PBB, PBDE, DBP, BBP, DEHP, DIBP, and 0.01% for cadmium, or qualify for an exemption to these limits as defined in the Annexes of Directive 2011/65/EU (RoHS2). Finished electrical and electronic equipment products will be CE marked as required by Directive 2011/65/EU. Components may not be CE marked. Additionally, the part numbers that TE has identified as EU ELV compliant have a maximum concentration of 0.1% by weight in homogenous materials for lead, hexavalent chromium, and mercury, and 0.01% for cadmium, or qualify for an exemption to these limits as defined in the Annexes of Directive 2000/53/EC (ELV). Regarding the REACH Regulation, the information TE provides on SVHC in articles for this part number is based on the latest European Chemicals Agency (ECHA) 'Guidance on requirements for substances in articles' posted at this URL: <https://echa.europa.eu/guidance-documents/guidance-on-reach>

### Compatible Parts

TE Part # 325154  
DIAMOND GRIP 12-10 HR R 10

TE Part # 323068  
DIAMOND GRIP 12-10 HR R 10

TE Part # 323067  
DIAMOND GRIP 12-10 HR R 8

TE Part # 323066  
DIAMOND GRIP 12-10 HR R 6

TE Part # 323069  
DIAMOND GRIP 12-10 HR R 1/4

TE Part # 323749  
DIAMOND GRIP 12-10 HT R 8

TE Part # 2-323683-1  
BODY BRAZ STRATO RNG 12-10 1/4

TE Part # 323757  
DIAMOND GRIP 12-10 HR BUTT

TE Part # 323751  
DIAMOND GRIP 12-10 HT R 1/4

TE Part # 323750  
DIAMOND GRIP 12-10 HT R 10

TE Part # 2-323750-5  
DIAMOND GRIP 12-10 HT R10 TAPE

TE Part # 323068-1  
DIAMOND GRIP 12-10 HR R 10TAPE



## Documents

### Product Drawings

[HHHT STRATO 12-10 ASSY](#)

English

### Datasheets & Catalog Pages

[Bottoming Dies](#)

English