

Fixture Type: \_\_\_\_\_

Catalog Number: \_\_\_\_\_

Project: \_\_\_\_\_

Location: \_\_\_\_\_

## York Flush Mount 3000K

Model & Size	Color Temp & CRI	Finish	Watt	LED Lumens	Delivered Lumens	Title 24
FM-45008 8"	3000K 90	AB Aged Brass	15W	873	449	YES
	3000K 90	BN Brushed Nickel	15W	873	449	YES

Example: **FM-45008-AB**

### DESCRIPTION

A timeless aesthetic. Lustrous aged brass or antiqued nickel and generous illumination for hallways and entryways.

### FEATURES

- ACLED driverless technology
- 5 Year warranty

### SPECIFICATIONS

<b>Color Temp:</b>	3000K
<b>Input:</b>	120 VAC, 50/60Hz
<b>CRI:</b>	90
<b>Dimming:</b>	ELV: 100-10%
<b>Rated Life:</b>	50000 Hours
<b>Mounting:</b>	Can be mounted on ceiling or wall horizontally or upside down
<b>Standards:</b>	ETL, cETL, Title 24: 2019 Damp Location Listed
<b>Construction:</b>	Aluminum hardware with tempered glass diffuser




### FINISHES



Aged Brass

Brushed Nickel

### LINE DRAWING

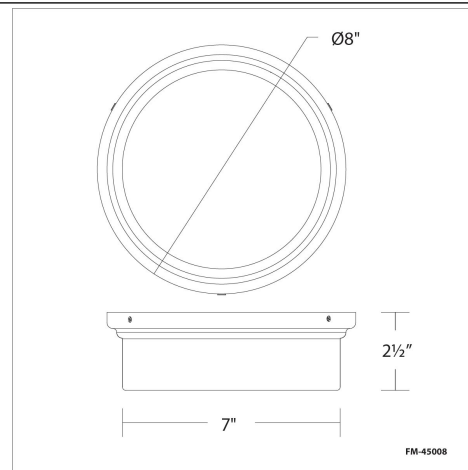

Fixture Type: \_\_\_\_\_

Catalog Number: \_\_\_\_\_

Project: \_\_\_\_\_

Location: \_\_\_\_\_

## York Flush Mount 3000K

Model & Size	Color Temp & CRI	Finish	Watt	LED Lumens	Delivered Lumens	Title 24
FM-45012 12"	3000K 90	AB Aged Brass	27W	1845	1071	YES
	3000K 90	BN Brushed Nickel	27W	1845	1071	YES

Example: **FM-45012-AB**

### DESCRIPTION

A timeless aesthetic. Lustrous aged brass or antiqued nickel and generous illumination for hallways and entryways.

### FEATURES

- ACLED driverless technology
- 5 Year warranty

### SPECIFICATIONS

<b>Color Temp:</b>	3000K
<b>Input:</b>	120 VAC, 50/60Hz
<b>CRI:</b>	90
<b>Dimming:</b>	ELV: 100-10%
<b>Rated Life:</b>	50000 Hours
<b>Mounting:</b>	Can be mounted on ceiling or wall horizontally or upside down
<b>Standards:</b>	ETL, cETL, Title 24: 2019 Damp Location Listed
<b>Construction:</b>	Aluminum hardware with tempered glass diffuser



### FINISHES



Aged Brass

Brushed Nickel

### LINE DRAWING

