


MORPHEUS III 60" Ceiling Fan

FR-W1813-60L

MODERN FORMS SMART FANS

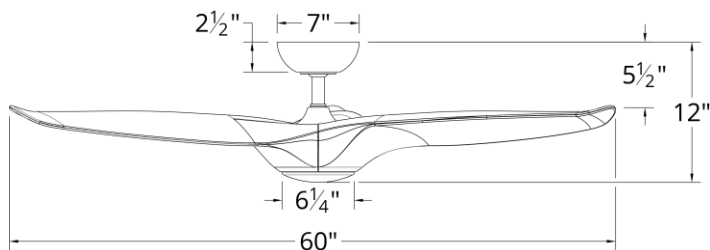

PRODUCT DESCRIPTION

With cutting-edge smart controls and a totally quiet DC motor, Morpheus is a sleek piece of luxury in a stylish two- or three-blade design. Like all our smart fans, Morpheus connects through Wi-Fi to our exclusive Modern Forms app, so it doesn't matter if you're five feet away or five hundred miles away- control is always in the palm of your hand. A powerful LED luminaire with artisan-crafted opal glass and thick aerodynamically soundless blades round out the design. Available in four amazing finishes.

SPECIFICATIONS

Construction: ABS
Blade: 12° Pitch, 60" sweep, ABS
Downrod: 1" O.D. x 6"H included
Mounting Slope: Up to 32°
Lead Wire: 80"
Hanging Weight: 14 lbs
Total Power: 50.5W
Standards: UL/cUL Wet Location listed, Title 24 JA8-2016 Compliant, Title 20, Energy Star

FEATURES

- 6 fan speeds through both Summer and Winter Modes
- Silent DC motor
- Optional LED light kit included
- Includes BT remote control with wall cradle
- Optional BT wall control sold separately
- Compatible with Modern Forms app

LIGHT KIT PERFORMANCE

Light Source: LED
Light Wattage: 19.5
Dimming: Integrated
Color Temperature: 3000K (2700K / 3500K options available)
Rated Life: 50,000 Hours
Standards: Title 24 JA8-2016 Compliant

ESTIMATED AIR PERFORMANCE

Airflow: 7490 cubic ft per minute on high
Power: 31 watts on high
Airflow Efficiency: 243 cubic ft per minute per watt
Revolutions Per Minute: 142 RPMs on high
Estimated Yearly Energy Cost (\$): \$5.70

WIRELESS PERFORMANCE

Bluetooth Range: Up to 150 ft*
Wi-Fi Range: Up to 150 ft*

ORDER NUMBER

Model	LED Lumens	Delivered Lumens	Housing	Blade
FR-W1813-60L	1600	1142	GB Gloss Black	Gloss Black
			GW Gloss White	Gloss White
			AS Automotive Silver	Automotive Silver

Example: **FR-W1813-60L-GW**

For 2700K add "-27"; 3500K add "-35" before the finish: **FR-W1813-60L-27-GW**

*Results may vary based on application and surroundings.



modernforms.com
 Phone (866) 810.6615
 Fax (800) 526.2585

Headquarters/Eastern Distribution Center
 44 Harbor Park Drive
 Port Washington, NY 11050

Central Distribution Center
 1600 Distribution Ct
 Lithia Springs, GA 30122







Western Distribution Center
 1750 Archibald Avenue
 Ontario, CA 91760

MORPHEUS III 60" Ceiling Fan

FR-W1813-60L

MODERN FORMS
SMART FANS

OPTIONAL ACCESSORIES

- BT Wall Control		F-WCBT	WT White	Control fan speed and light brightness, and switch between Summer and Winter Modes. Additional Wall Controls can be purchased separately for multiple location control.
BT Remote Control		F-RCBT	WT White	Control fan speed and light brightness, and switch between Summer and Winter Modes. Compatible with Modern Forms Smart Fans. Includes easy-to-install wall cradle and batteries.
Wi-Fi Touch Panel Wall Control		F-TS	BK Black WT White	Sold separately. Android tablet comes pre-loaded with Modern Forms app, Wi-Fi range up to 150 ft from router. Results may vary based on application/surroundings.
Downrod		XF-12 12in XF-18 18in XF-24 24in XF-36 36in XF-48 48in XF-60 60in XF-72 72in	AS Automotive Silver BA Brushed Aluminum BZ Bronze CFI Carbon Fiber** DW Dark Walnut GB Gloss Black GH Graphite GW Gloss White KO Koat MB Matte Black Matte MW White OB Oil Rubbed Bronze SS Stainless Steel TT Titanium Silver	All our downrods are 1" O.D. and are threaded on the motor end to create an extra layer of security and allow for adjustments in the field.
Downrod Couplers		XF-I		Connects two downrods together.
Sloped Ceiling Kit		XF-SCK		Designed to accommodate buildings with steeper sloped ceilings up to 45° or 12/12 pitch.

Examples: RF Wall Control - **F-WC-WT**, RF Remote Control - **F-RC-WT**, Wi-Fi Touch Panel - **F-TS-WT**, Downrod - **XF-12-BZ**, Downrod Coupler - **XF-I-BZ**, Sloped Ceiling Kit - **XF-SCK-DW**

SUGGESTED DOWNROD HEIGHT USAGE

Ceiling Height	15'	14'	13'	12'	11'	10'	9'
Downrod	72"	60"	48"	36"	24"	18"	12"

SLOPED CEILING DEGREE CONVERSION CHART

Degree	4-8°	9-13°	14-17°	18-21°	22-25°	26-29°	30-32°	33-35°	36-38°	39-41°	42-44°	45°
Ceiling Slope Pitch	1/12 pitch	2/12 pitch	3/12 pitch	4/12 pitch	5/12 pitch	6/12 pitch	7/12 pitch	8/12 pitch	9/12 pitch	10/12 pitch	11/12 pitch	12/12 pitch

Supplied mounting brackets allow mounting on ceiling slopes up to 30° (7/12 pitch). Optional slope kit allows mounting on ceilings up to 45° (12/12 pitch). The receiver will mount inside canopy up to 45°.

NOTE: Recommended maximum downrod length of 72" with 80" lead wire

**Carbon Fiber downrods available in 12", 18", 24" and 36"

†Koa downrods available in 12", 18", 24" and 36"

modernforms.com	Headquarters/Eastern Distribution Center	Central Distribution Center	Western Distribution Center
Phone (866) 810.6615	44 Harbor Park Drive	1600 Distribution Ct	1750 Archibald Avenue
Fax (800) 526.2585	Port Washington, NY 11050	Lithia Springs, GA 30122	Ontario, CA 91760