


VIBE - model: PL-LED

LED Picture Lights

WAC LIGHTING

Responsible Lighting®

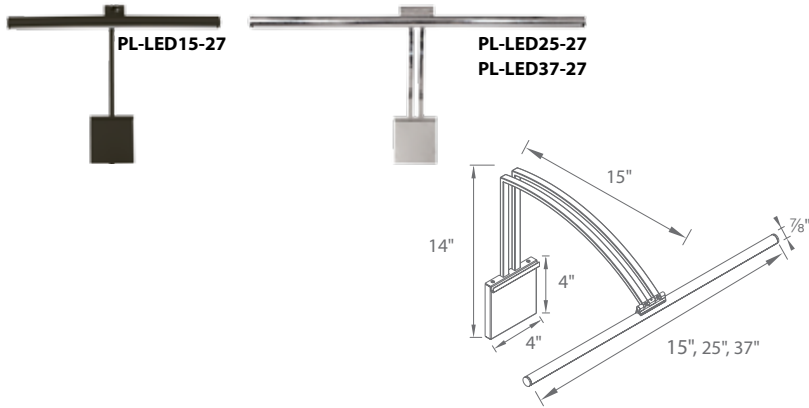

Fixture Type:

Catalog Number:

Project:

Location:

PRODUCT DESCRIPTION

Designed to disappear, the low profile Vibe picture light features a canopy that both hides behind the artwork and serves as the mount. At less than an inch in diameter, the Vibe picture light shrouds the smallest light source available to provide substantial, full spectrum, and high quality lighting. Three lengths with 35 degree rotation accommodates artwork of varying sizes.

FEATURES

- Head rotates 35° up or down
- 110° beam angle
- Meets 2013 California Title 24 Efficiency
- Replaceable LED module
- For portable models, 8 foot cord & plug with 18" wire cover in matching finish included
- 70,000 hour rated life

SPECIFICATIONS

Construction: Aluminum with frosted plastic lens

Power: Integral driver, no remote driver needed

Light Source: Direct wiring or plug-in LED

Mounting: Hard wired and plug-in models available

Dimming: Dim to 10% with electronic low voltage (ELV) dimmer.

Finish: Black (BK), Brushed Nickel (BN), Chrome (CH) and Satin Brass (SB)


Standards: ETL & cETL Listed

FIXTURE PERFORMANCE

Model #	Watt	Photometric Lumens	Delivered Lumens	Efficacy
PL-LED15-27	8.5W	595	240	28 Lm/W
PL-LED25-27	16W	1186	535	33 Lm/W
PL-LED37-27	23W	1785	850	37 Lm/W

ORDER NUMBER

	Model	Length	Finish	
Hard Wired	PL-LED	15-27 15"	BK Black	
		25-27 25"	BN Brushed Nickel	
		37-27 37"	CH Chrome	
Portable	PL-LED	15P-27 15"	SB Satin Brass	
		25P-27 25"	BK Black	
		37P-27 37"	BN Brushed Nickel	

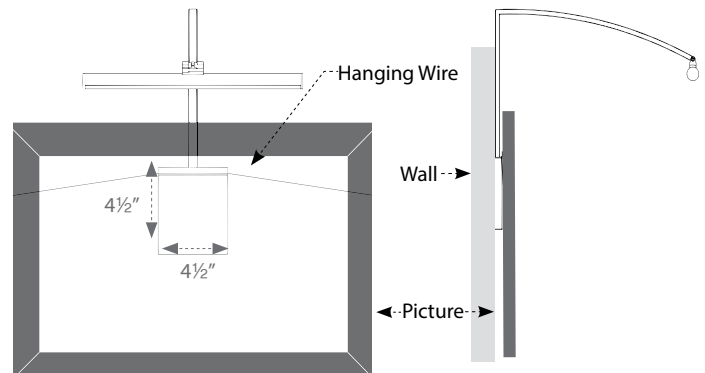

PL-LED -

Example: **PL-LED15-27-BK**

WAC Lighting
www.waclighting.com
Phone (800) 526.2588 • Fax (800) 526.2585

Headquarters/Eastern Distribution Center
44 Harbor Park Drive • Port Washington, NY 11050
Phone (516) 515.5000 • Fax (516) 515.5050

Western Distribution Center
1750 Archibald Avenue • Ontario, CA 91760
Phone (800) 526.2588 • Fax (800) 526.2585