

ARCHTYPE - LED Outdoor Post Mount

PM-W15928

dweLED
by WAC Lighting



Fixture Type:

Catalog Number:

Project: _____

Location: _____

PRODUCT DESCRIPTION

A low-profile, artful design adds a distinctive, sophisticated look in any outdoor application.

FEATURES

- No transformer or driver needed
- Mount on 3" post (maximum, not included)
- Color Temperature: 3000K
- CRI: 90
- Rated Life: 54,000 hours

SPECIFICATIONS

Construction: Aluminum hardware with etched glass diffuser


Input: 120V

Dimming: 100% - 10% ELV

Light Source: High output LED

Finish: Black (BK)

Standards: ETL/cETL, Wet location listed, JA8 2016 Title 24 Compliant, Dark Sky friendly

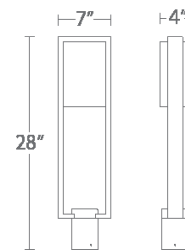

PD-W15928

ORDER NUMBER

Model	Size	Watt	LED Lumens	Delivered Lumens	Finish
PM-W15928	28"	16W	1200	382	BK Black 

Example: **PM-W15928-BK**

dweLED.com
Phone (800) 526.2588
Fax (800) 526.2585

Headquarters/Eastern Distribution Center
44 Harbor Park Drive
Port Washington, NY 11050

Central Distribution Center
1600 Distribution Ct
Lithia Springs, GA 30122

Western Distribution Center
1750 Archibald Avenue
Ontario, CA 91760