

Fixture Type: _____

Catalog Number: _____

Project: _____

Location: _____

Atlantis Outdoor Wall Sconce

Model & Size	Color Temp & CRI	Watt	LED Lumens	Delivered Lumens	Finish
WS-W27106 6"	3000K 90	9W	181	113	AL Brushed Aluminum
	3500K 90	9W	207	130	BK Black
	4000K 90	9W	180	113	WT White

Example: **WS-W27106-30-AL**

DESCRIPTION


Searching the depths. Illuminating all that matters.

FEATURES


- 3CCT (3000K/3500K/4000K) selectable switch
- ACLED driverless technology
- 5 year warranty

SPECIFICATIONS


Color Temp:	4000K, 3500K, 3000K
Input:	120 VAC, 50/60Hz
CRI:	90
Dimming:	ELV: 100-10%, TRIAC: 100-10%
Rated Life:	54000 Hours
Mounting:	Can be mounted on wall in all orientations
Standards:	ETL, cETL, IP65
	Wet Location Listed
Construction:	Aluminum body, tempered glass diffuser

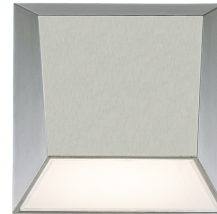

FINISHES

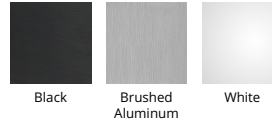

LINE DRAWING

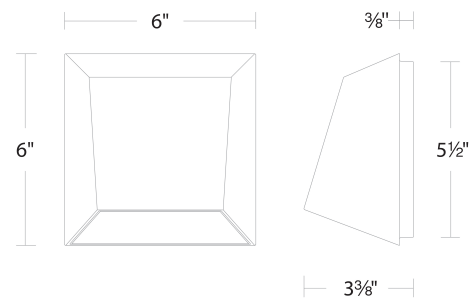

WS-W27106