



SPA – model: WS-W417
 dwelLED™ LED Outdoor

WAC LIGHTING
 Responsible Lighting®

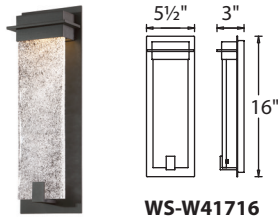

WS-W41716

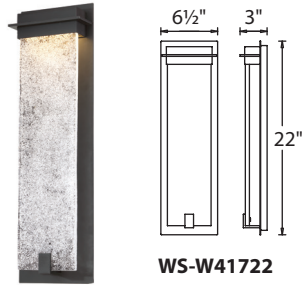

WS-W41722

Fixture Type:

Catalog Number:

Project: _____

Location: _____


PRODUCT DESCRIPTION

A dazzling and shimmering sparkle of light, Spa features a hand poured pane of art glass that creates beautiful and dramatic patterns of light when illuminated. Built with solid die cast aluminum hardware that is weather resistant with a powder coated finish. The light engine is factory sealed for maximum protection against the harshest elements.

FEATURES

- Hand poured pane of art glass creates beautiful, dramatic patterns of light
- Weather resistant powder coated finish
- Light engine is factory sealed for maximum protection from the elements
- Solid aluminum construction
- No transformer or driver required
- Color Temp: 3000K
- CRI: 90
- Dimming: 100% - 0% ELV
- Rated Life: 54,000 hours
- Input: 120V

ORDER NUMBER

		Watt	LED Lumens	Delivered Lumens	Finish
16"	WS-W41716	12.5W	375	185	BZ Bronze 
22"	WS-W41722	12.5W	365	180	

Example: **WS-W41716-BZ**

SPECIFICATIONS

Construction: Aluminum and Clear Crystal Art Glass

Light Source: High output LED.

Finish: Bronze (BZ)

Standards: ETL & cETL wet location listed. IP 65. CEC Title 24

waclighting.com
 Phone (800) 526.2588
 Fax (800) 526.2585

Headquarters/Eastern Distribution Center
 44 Harbor Park Drive
 Port Washington, NY 11050

Central Distribution Center
 1600 Distribution Ct
 Lithia Springs, GA 30122

Western Distribution Center
 1750 Archibald Avenue
 Ontario, CA 91760