

## Item Number 7307000

## Porto Ceiling Fan

52 in. Distressed Aluminum Finish  
Reversible Blades (Charcoal/Rustic Birch) Opal Frosted Glass

### Specifications

|                          |   |
|--------------------------|---|
| Size .....               | 52"   |
| Blades.....              | Reversible Plywood Blades<br>(Charcoal/Rustic Birch)        |
| Blade Pitch.....         | 12°   |
| Approved Location .....  | Indoor  |
| Suggested Room Size..... | Large Room (up to 15x15)                                    |
| Down Rod.....            | 3/4 x 4"  |
| Installation.....        | Combo   |
| Max. Ceiling Angle.....  | N/A   |
| Lead Wire .....          | 54"   |
| Light Bulb Usage.....    | Includes (1) Medium (E26) Base, 9 Watt Omni<br>A19 LED Lamp |
| Control .....            | Remote Control Included                                     |
| Motor Finish.....        | Distressed Aluminum   |
| Motor Material .....     | Silicon Steel Motor 153mm<br>x 15mm                         |
| Reverse Airflow.....     | Yes   |
| Capacitor .....          | Single  |
| Switch Housing Cap.....  | Not Included  |



### Energy Information

|   | <u>With down rod</u> | <u>Hugger/<br/>Without down rod</u> |
|---|----------------------|-------------------------------------|
| Airflow (CFM) when operated at high speed.....  | 4307                 | 3579                                |
| Energy Use (excludes lights) <sup>Δ</sup> ..... | 42                   | 42                                  |
| Airflow (CFM) <sup>Δ</sup> .....                | 3223                 | 2264                                |
| Airflow Efficiency (CFM/W) <sup>Δ</sup> .....   | 78                   | 54                                  |
| Estimated Yearly Energy Cost <sup>Δ</sup> ..... | \$12                 | \$12                                |
| RPM (High) .....                                | 176                  |                                     |
| Amp (High) .....                                | 0.52                 |                                     |
| Watts (High) .....                              | 61                   |                                     |

Reversible Rustic Birch  
Finish Blades



### Light Source

|   |        |
|---|--------|
| Number of Lamps.....                      | 1      |
| Energy Use (Watts) <sup>†</sup> .....     | 9      |
| Equiv. Incand. Wattage <sup>†</sup> ..... | 60     |
| Color Temperature (Kelvin).....           | 3000   |
| Color Designation: Warm White             |        |
| Lumen <sup>†</sup> .....                  | 800    |
| CRI.....                                  | 80     |
| Average Rated Hours.....                  | 25000  |
| Life in Years <sup>**†</sup> .....        | 22.80  |
| Estimated Yearly Energy Cost..            | \$1.08 |

Specifications are subject to change without notice, please visit [www.westinghouselighting.com](http://www.westinghouselighting.com) for latest information.

® and Westinghouse are trademarks of Westinghouse Electric Corporation.  
Used under license by Westinghouse Lighting. All Rights Reserved.


<sup>Δ</sup> Based on typical use, excluding lights  
<sup>\*</sup> Based on 12 cents per kWh and 6.4 hours use per day  
<sup>†</sup> Values are per lamp  
<sup>\*\*</sup> Based on 3hrs./day

## Item Number 7307000

## Porto Ceiling Fan

52 in. Distressed Aluminum Finish  
 Reversible Blades (Charcoal/Rustic Birch) Opal Frosted Glass

|  |       |
|--|-------|
| A. Top of Canopy to Bottom of Blades .....       | 10.8" |
| B. Top of Canopy to Bottom of Switch House ..... | 12.8" |
| C. Top of Canopy to Bottom of Canopy .....       | 2.7"  |
| D. Width of Motor Housing.....                   | 7.9"  |
| E. Width of Canopy.....                          | 5.2"  |
| F. Top of Canopy to Bottom of Glass.....         | 20.1" |

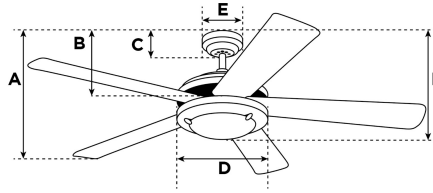

If a Combo Style Fan with a 4" Down Rod is installed without the Down Rod, Subtract 3" from the Dimensions Listed (A, B, F).  
 If a Combo Style Fan with a 6" Down Rod is installed without the Down Rod, Subtract 5" from the Dimensions Listed (A, B, F).

## Warranty

Ceiling fans backed by our Limited Lifetime Warranty have a lifetime motor warranty and a 2-year warranty on all other parts.

*Specifications are subject to change without notice, please visit [www.westinghouselighting.com](http://www.westinghouselighting.com) for latest information.*

 and Westinghouse are trademarks of Westinghouse Electric Corporation. Used under license by Westinghouse Lighting. All Rights Reserved.