



Are you looking for a  
**MORE POWERFUL  
AIR PURIFIER?**

You may have realized that strength alone isn't always enough, and you need something more practical. If you need to maintain clean indoor air in large, busy, or crowded areas, **XPOWER HAS EXACTLY WHAT YOU'RE LOOKING FOR.**



**POWERFUL**

Provides up to 1,800 CFM for fast and complete air purification in large spaces.



**ENERGY EFFICIENT**

Save 40% or more energy compared to a standard air purifier.



**NOISE LEVEL**

Incredibly quiet at the lowest setting. Perfect for air quality maintenance.



**VARIABLE SPEED**

Gives full control of noise level, energy consumption and airflow.



**DC BRUSHLESS MOTOR**

More advanced, high performance, & efficient than other motors.



**4-STAGE HEPA FILTRATION**


Highly efficient technology.

**Pre-Filter** ● ● ● ●

**Pleated Filter** ● ●

**Activated Carbon Filter** ● ●  
(Optional for AP-2500D)

**HEPA Filter** ● ● ● ●

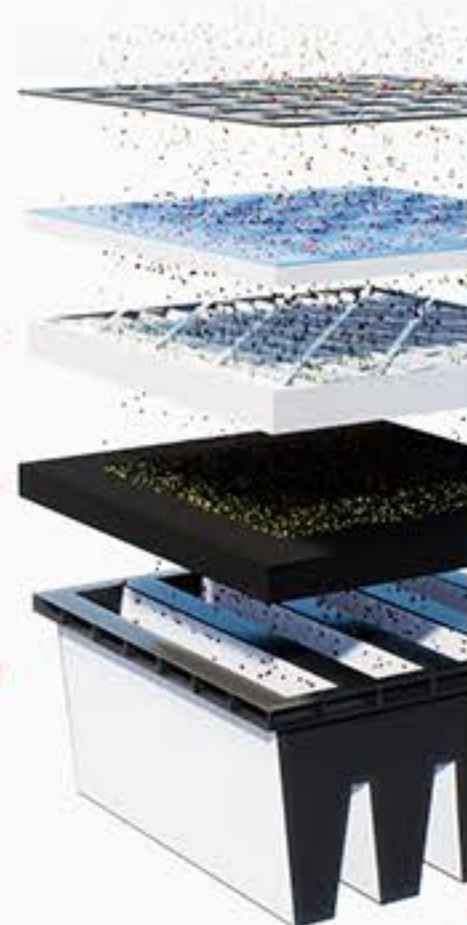

**PRECISE AIRFLOW**

Full control with variable speed function.

CLEAN EFFECTIVELY  
**1,000 SQ.FT**  
IN JUST A QUICK  
**5 MINS**



**LARGE COVERAGE**

Powerful DC motor provides wider & further coverage.



**AIR QUALITY SENSOR**

Filters the indoor air efficiently with digital real-time color-coded PM2.5 air quality monitor.



**FILTER CHANGE INDICATOR**

Pressure gauge indicates when filter may need to be replaced.



**AP-2500D**  
Smart Air Purifier



**AP-1800D**  
Smart Air Purifier



**AP-1500D**  
Smart Air Purifier

<b>Max Airflow</b>	1,800 CFM	1,100 CFM	700 CFM
<b>Motor</b>	DC Brushless Motor	DC Brushless Motor	DC Brushless Motor
<b>Amperage</b>	8 A	3.5 A	1.5 A
<b>Speed</b>	Variable Speed	Variable Speed	Variable Speed
<b>Unit Weight</b>	98.66 Lbs.	65.7 Lbs.	45.9 Lbs.
<b>Dimensions</b>	29.4 x 26.7 x 38.8 in.	37.2 x 25.2 x 22.6 in.	19.4 x 21.9 x 35.8 in.