

**Model: 6247XXXX**



### FEATURES

- Energy Efficient and Long-Lasting LED Lighting
- Frosted Pattern Around All Sides
- Aluminum Mirror Frame for a Clean and Modern Look
- Smart Touch Control Switch
- 5mm Copper-free Mirror
- Surface-Mount with French Cleat
- Hardwired (Junction box required)

### LIGHTING


- LED (Light-Emitting Diode)
- Average Bulb Life of 50,000 hours
- CRI: 85+
- Dual Color Temperature: 2700K & 6400K
- Compatible with Wall Dimmers
- Brightness & Power Consumption: See Page 2
- Power Requirements: 110-130V AC, 60Hz

### SAFETY

- Safety Backed Mirror
- IP44 Rated
- UL Listed

### OVERVIEW

**innoci-usa** does not cut corners and only uses the highest quality components and bulbs to make sure that the mirror will be maintenance free and function like the day you purchased for average 50,000 hours of use. **innoci-usa** prides itself on providing unmatched price vs quality for all of our products. All mirrors come with a 5-year limited warranty.

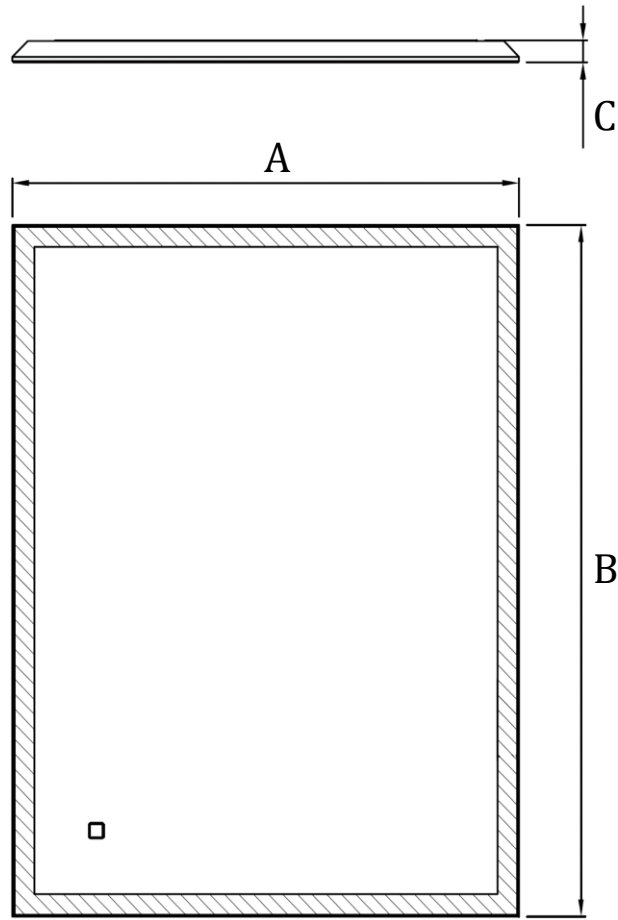

| Model #  | A  | B  | C | Brightness (Lumen) | Power Consumption (Watt) |
|----------|----|----|---|--------------------|--------------------------|
| 62472432 | 24 | 32 | 1 | 2754               | 23.5                     |
| 62473224 | 32 | 24 | 1 | 2754               | 23.5                     |
| 62473656 | 36 | 56 | 1 | 4752               | 44                       |
| 62475636 | 56 | 36 | 1 | 4752               | 44                       |

innoci-usa Inc.  
Newport Beach, CA 92660

[www.innoci-usa.com](http://www.innoci-usa.com)  
(866) 479-8076

[customerservice@innoci-usa.com](mailto:customerservice@innoci-usa.com)

**innociusa**  
L I F E S T Y L E