


Model: 6280XXXX

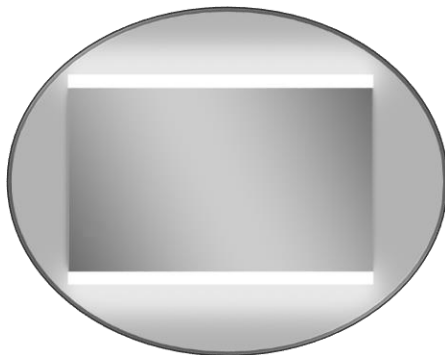

NOTE: Items other than the mirror shown in the pictures above are not included

OVERVIEW

Innoci-usa does not cut corners and only uses the highest quality components and bulbs to make sure that the mirror will be maintenance free and function like the day you purchased for average 50,000 hours of use. Innoci-usa prides itself on providing unmatched price vs quality for all of our products. All mirrors come with a 5-year limited warranty.

FEATURES


- Energy Efficient and Long-Lasting LED Lighting
- 2-Side Forward-Facing Lighting with Back Lit
- Smart Touch Control Switch
- Acrylic Light Diffuser
- 5mm Copper-Free Mirror
- Durable Aluminum Frame
- Surface-Mount with French Cleat Mounting Bracket
- Hardwired (Junction box required)
- 2-Way Hanging (Portrait & Landscape)

LIGHTING

- LED (Light-Emitting Diode)
- Average Bulb Life of 50,000 hours
- CRI: 85+
- Dual Color Temperature: 3000K & 6000K
- Compatible with Wall Dimmers
- Brightness & Power Consumption: See Page 2
- Power Requirements: 110-130V AC, 60Hz

SAFETY

- Safety Backed Mirror
- IP44 Rated
- UL Certified

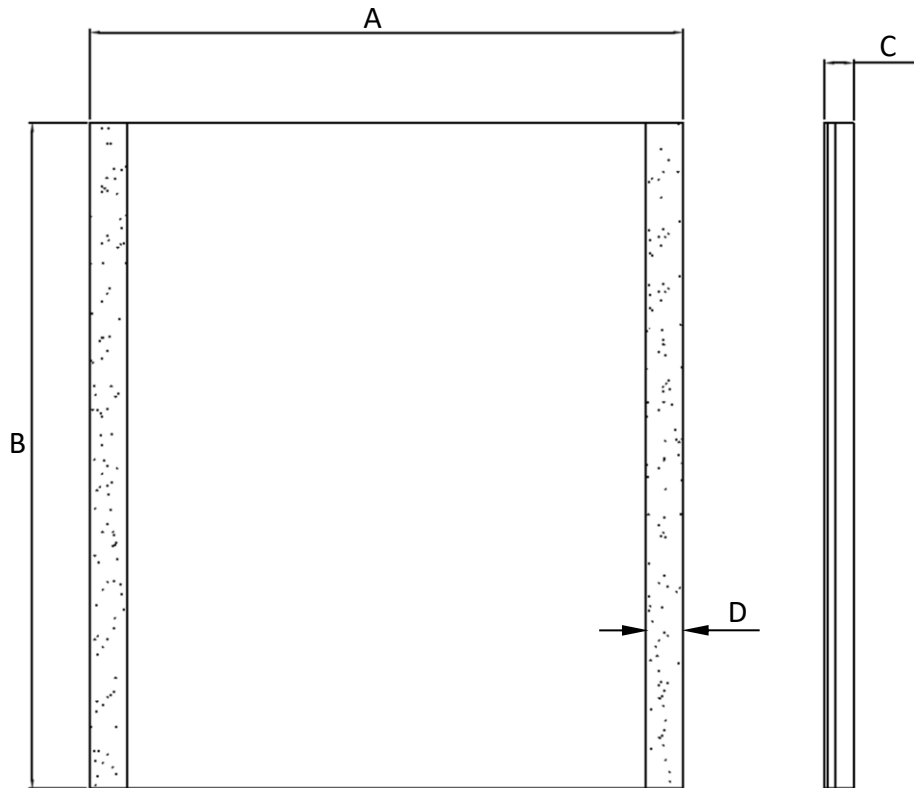

Model #	A	B	C	D	Brightness (Lumen)	Power Consumption (Watt)
62802435	24	35	1-9/16	1-1/2	3150	38.5
62803524*	35	24		1-1/2	3150	38.5
62803236	32	36		2	3240	39.6
62803632*	36	32		2	3240	39.6
62804636	46	36		3	3240	39.6
62803646*	36	46		3	3240	39.6
62805636	56	36		4	3240	39.6
62803656*	36	56		4	3240	39.6

* Frosted patterns are located at the top and bottom of the mirror for these models.