

Model: 6300XXXX



FEATURES

- Energy Efficient and Long Lasting LED Lighting
- Acrylic Light Diffuser
- Mirror Front IR Sensor Switch
- 5mm Copper-free Mirror
- Durable Aluminum Frame
- Surface-Mount with French Cleat Mounting Bracket
- Hardwired (Junction box required)

LIGHTING


- Front-facing and Back-lit Lighting
- Average Bulb Life of 50,000 hours
- Color Temperature: 6000K (Daylight)
- Brightness & Power Consumption: See Page 2
- Power Requirements: 110-130V AC, 60Hz

SAFETY

- Safety Backed Mirror
- IP44 Rated
- UL listed

OVERVIEW

innoci-usa does not cut corners and only uses the highest quality components and bulbs to make sure that the mirror will be maintenance free and function like the day you purchased for average 50,000 hours of use. **innoci-usa** prides itself on providing unmatched price vs quality for all of our products. All mirrors come with a 5-year limited warranty.

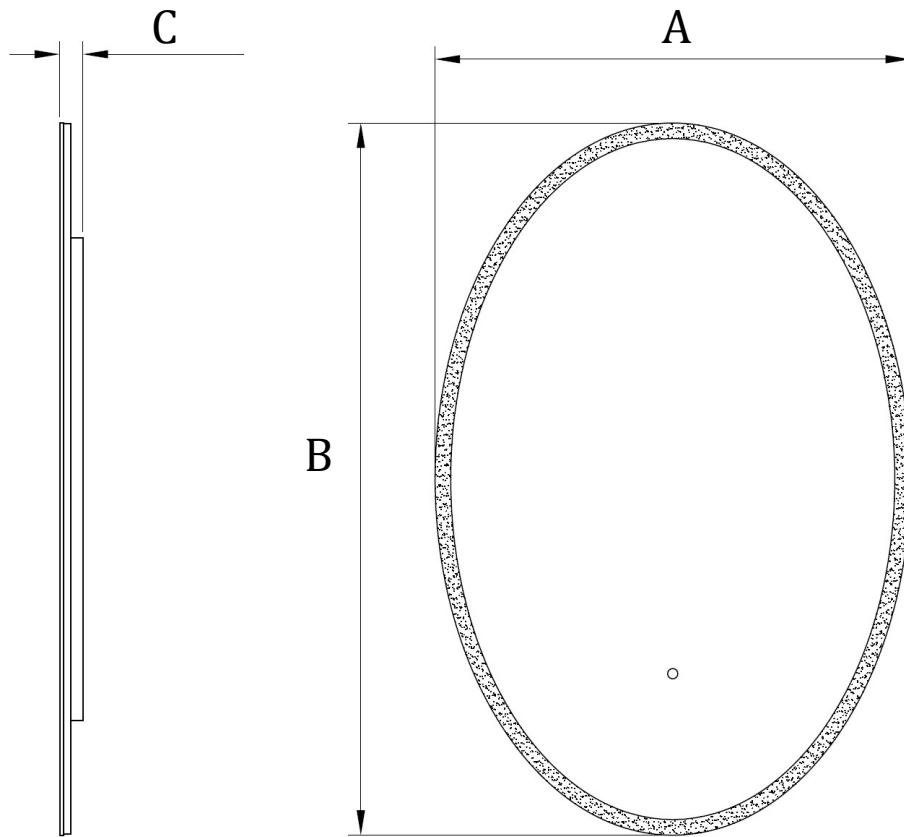

Model #	A	B	C	Brightness (Lumen)	Power Consumption (Watt)
63002020	20	20	1 1/8	810	13
63002226	22	26	1 1/8	1050	16
63002424	24	24	1 1/8	1035	17
63002436	24	36	1 1/8	1350	22
63003030	30	30	1 1/8	1290	20
63003636	36	36	1 1/8	1620	26

innoci-usa Inc.
Newport Beach, CA 92660

www.innoci-usa.com
(866) 479-8076

customerservice@innoci-usa.com

innociusa
LIFESTYLE