

**Model: 6340XXXX**



(Items other than the mirror shown in the picture above are not included)

### FEATURES

- Energy Efficient and Long-Lasting LED Lighting
- Frosted Pattern Around All Sides
- Mirror on Two Sides to Provide Cleaner Look.
- Dual Switches (Rocker & IR Sensor) for Added Convenience
- 5mm Copper-Free Mirror
- Durable Aluminum Frame with Steel Back Panel
- Surface-Mount with French Cleat Mounting Bracket
- Hardwired (Junction box required)

### LIGHTING

- Front-Facing Lighting
- Average Bulb Life of 50,000 hours
- CRI: 85+
- Color Temperature: 6000K (Daylight)
- Dimmable using Built-in IR Sensor\*
- Brightness & Power Consumption: See Page 2
- Power Requirements: 110-130V AC, 60Hz


### SAFETY

- Safety Backed Mirror
- IP44 Rated
- UL Listed

**\* Not compatible with wall dimmer switch.**

### OVERVIEW

**innoci-usa** does not cut corners and only uses the highest quality components and bulbs to make sure that the mirror will be maintenance free and function like the day you purchased for average 50,000 hours of use. **innoci-usa** prides itself on providing unmatched price vs quality for all of our products. All mirrors come with a 5-year limited warranty.

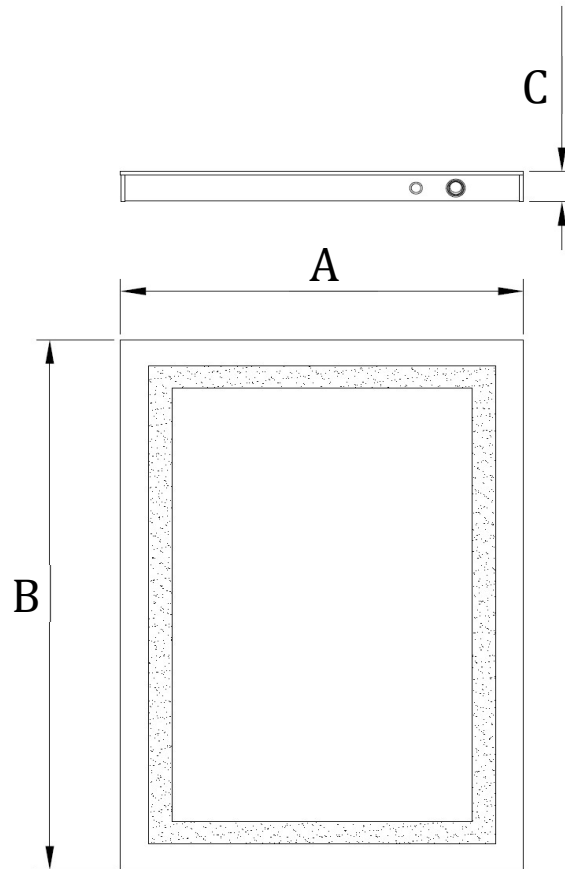

Model #	A	B	C	Brightness (Lumen)	Power Consumption (Watt)
63402028	20	28	1 5/8	1230	20
63402432	24	32	1 5/8	1470	24
63402820	28	20	1 5/8	1230	20
63403224	32	24	1 5/8	1470	24
63403232	32	32	1 5/8	1728	28
63404040	40	40	1 5/8	2220	36
63405636	56	36	1 5/8	2580	42
63406028	60	28	1 5/8	2478	40

© innoci usa, Inc. All rights reserved.

innoci-usa Inc.  
Santa Fe Springs, CA 90670

[www.innoci-usa.com](http://www.innoci-usa.com)  
(866) 479-8076

[customerservice@innoci-usa.com](mailto:customerservice@innoci-usa.com)

**innociusa**  
L I F E S T Y L E

rev1.8