

Model: 6350XXXX



(Items other than the mirror shown in the picture above are not included)

FEATURES

- Energy Efficient and Long-Lasting LED Lighting
- Acrylic Light Diffuser for Backlit Lighting
- 5mm Copper-Free Mirror
- Mirror Font IR Sensor Switch for Added Convenience
- Durable Aluminum Frame with Steel Back Panel Surface-Mount with French Cleat Mounting Bracket
- Hardwired (Junction box required)

LIGHTING


- Front-Facing & Backlit lighting
- Average Bulb Life of 50,000 hours
- CRI: 85+
- Color Temperature: 6000K (Daylight)
- Brightness & Power Consumption: See Page 2
- Power Requirements: 110-130V AC, 60Hz

SAFETY

- 5mm Safety Backed Mirror
- IP44 Rated
- UL Listed

OVERVIEW

innoci-usa does not cut corners and only uses the highest quality components and bulbs to make sure that the mirror will be maintenance free and function like the day you purchased for average 50,000 hours of use. **innoci-usa** prides itself on providing unmatched price vs quality for all of our products. All mirrors come with a 5-year limited warranty.

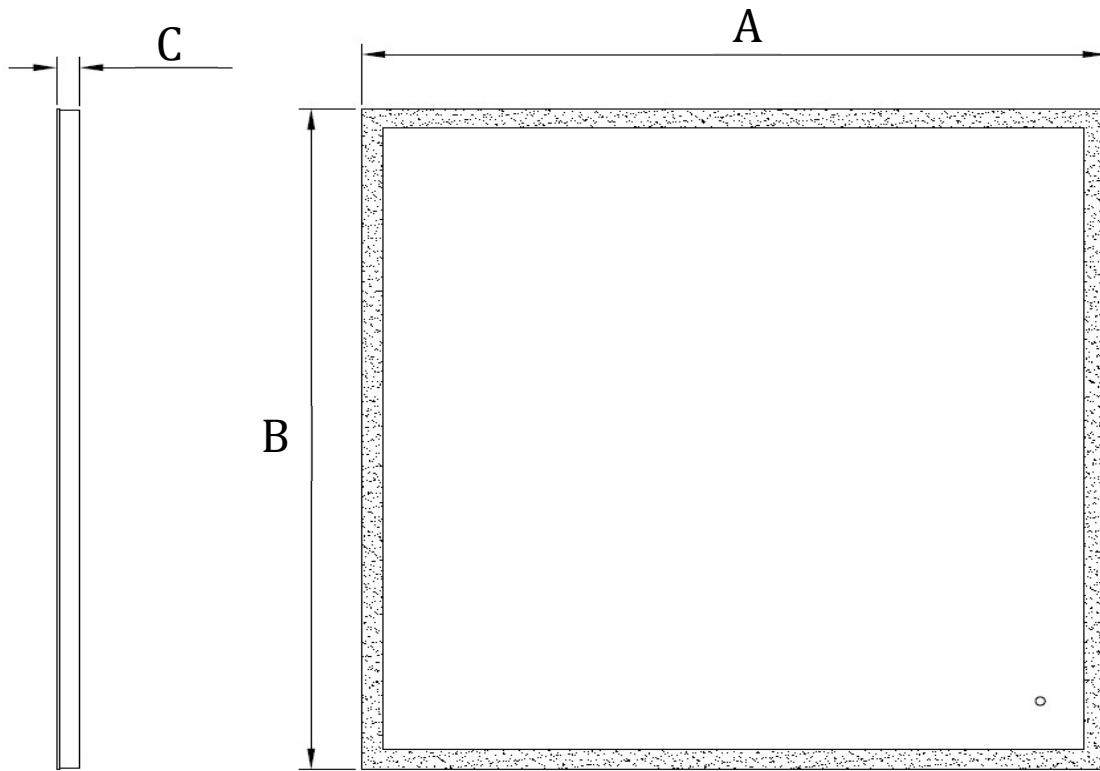

Model #	A	B	C	Brightness (Lumen)	Power Consumption (Watt)
63502432	24	32	1-1/4	1530	25
63502448	24	48		2010	33
63503224	32	24		1530	25
63503546	35	46		2280	37
63503656	36	56		2610	42
63504040	40	40		2250	36
63504635	46	35		2280	37
63504824	48	24		2010	33
63505636	56	36		2610	42
63507230	72	30		2910	47

© **innoci usa, Inc.** All rights reserved.

innoci-usa Inc.
Santa Fe Springs, CA 90670

www.innoci-usa.com
(866) 479-8076

customerservice@innoci-usa.com

innociusa
LIFESTYLE

rev7.8