

**Model: 6360XXXX**



(Faucets and other display items not included)

### FEATURES

- Elegant Rounded Corner Design
- Energy Efficient and Long Lasting LED Lighting
- Frosted pattern on four sides
- 5mm Copper-Free Mirror
- Mirror Front IR Sensor Switch
- Durable Aluminum Frame with Steel Back Panel Surface-Mount with French Cleat Mounting Bracket
- Hardwired (Junction box required)

### LIGHTING


- Front-Facing & Backlit Lighting
- Acrylic Light Diffuser
- CRI: 85+
- Average Bulb Life of 50,000 hours
- Color Temperature: 6000K (Daylight)
- Brightness & Power Consumption: See Page 2
- Power Requirements: 110-130V AC, 60Hz

### SAFETY

- Safety Backed Mirror
- IP44 Rated
- UL Listed

### OVERVIEW

**innoci-usa** does not cut corners and only uses the highest quality components and bulbs to make sure that the mirror will be maintenance free and function like the day you purchased for average 50,000 hours of use. **innoci-usa** prides itself on providing unmatched price vs quality for all of our products. All mirrors come with a 5-year limited warranty.

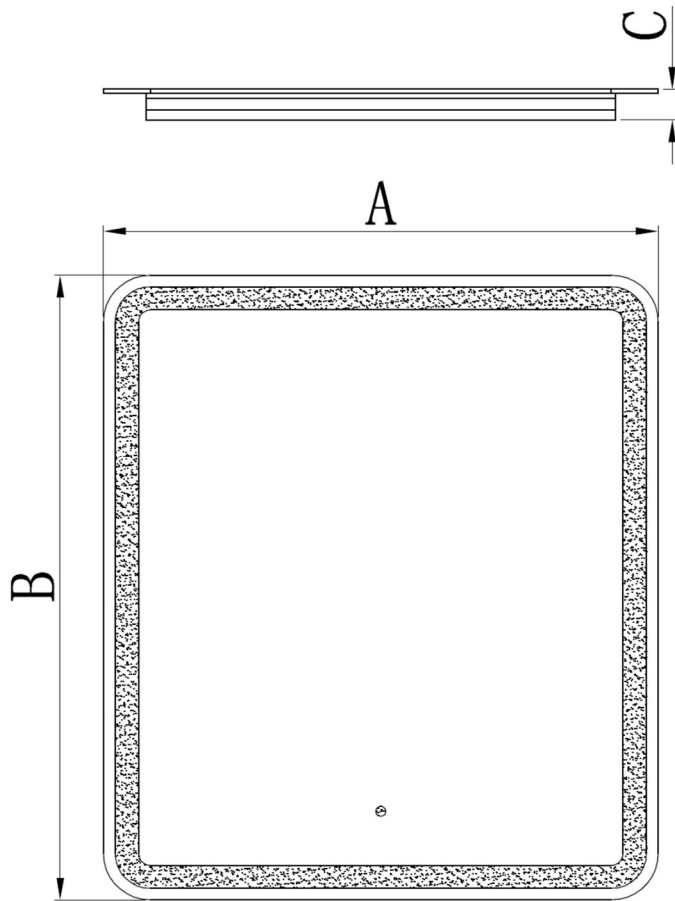

Model #	A	B	C	Brightness (Lumen)	Power Consumption (Watt)
63602432	24	32	1 5/8	1510	25
63602832	28	32	1 5/8	1590	26
63603224	32	24	1 5/8	1510	25
63603228	32	28	1 5/8	1590	26
63605035	50	35	1 5/8	2300	37
63606036	60	36	1 5/8	2640	43
63606228	62	28	1 5/8	2450	40

innoci-USA Inc.  
Newport Beach, CA 92660

[www.innoci-usa.com](http://www.innoci-usa.com)  
(866) 479-8076

[customerservice@innoci-usa.com](mailto:customerservice@innoci-usa.com)

**innociusa**  
LIFESTYLE