

**Model: 6370XXXX**



### FEATURES

- Elegant Rounded Corner Design
- Energy Efficient and Long Lasting LED Lighting
- Frosted pattern on four sides
- 5mm Copper-free Mirror
- Mirror Front IR Sensor Switch
- Acrylic Light Diffuser
- Surface-Mount with French Cleat Mounting Bracket
- Hardwired (Junction box required)

### LIGHTING

- Front-facing & Back-lit Lighting
- Average Bulb Life of 50,000 hours
- CRI: 85+
- Brightness & Power Consumption: See Page 2
- Power Requirements: 110-130V AC, 60Hz

### SAFETY

- Safety Backed Mirror
- IP44 Rated
- UL Listed


### OVERVIEW

**innoci-usa** does not cut corners and only uses the highest quality components and bulbs to make sure that the mirror will be maintenance free and function like the day you purchased for average 50,000 hours of use. **innoci-usa** prides itself on providing unmatched price vs quality for all of our products. All mirrors come with a 5-year limited warranty.

innoci-usa Inc.  
Newport Beach, CA 92660

[www.innoci-usa.com](http://www.innoci-usa.com)  
(866) 479-8076

[customerservice@innoci-usa.com](mailto:customerservice@innoci-usa.com)

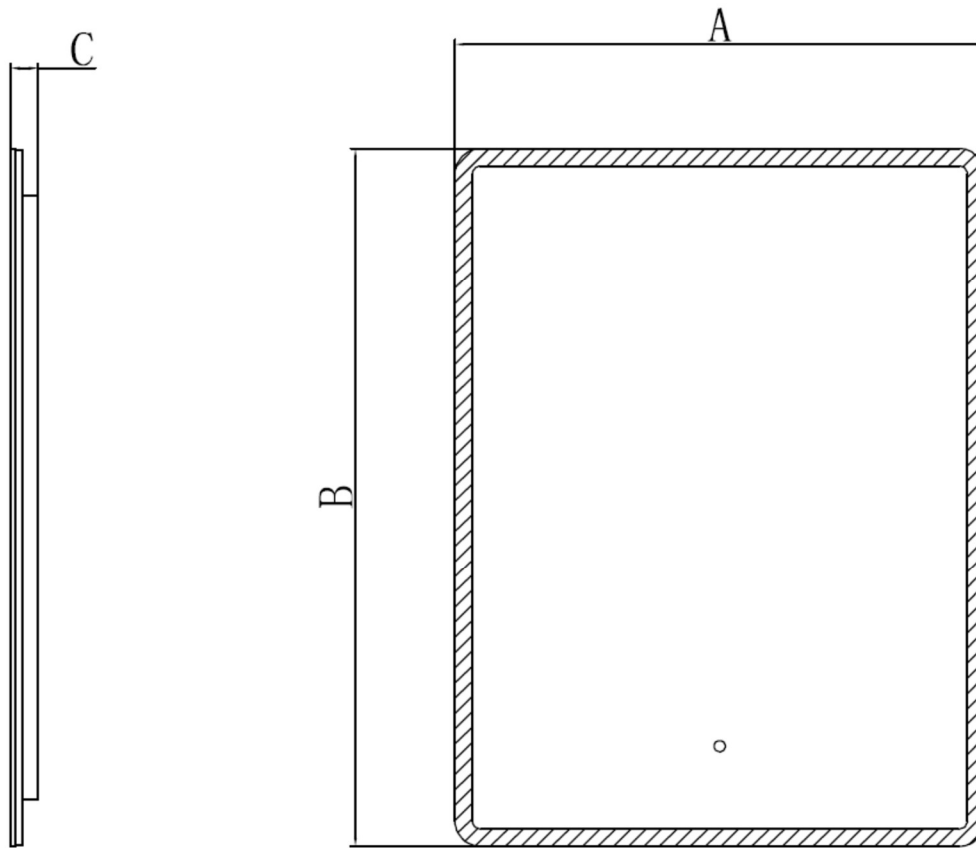

Model #	A	B	C	Brightness (Lumen)	Power Consumption (Watt)
63702432	24	32	1 1/8	1560	25
63703632	36	32	1 1/8	1890	31

innoci-usa Inc.  
Newport Beach, CA 92660

[www.innoci-usa.com](http://www.innoci-usa.com)  
(866) 479-8076

[customerservice@innoci-usa.com](mailto:customerservice@innoci-usa.com)

**innoci**usa  
LIFESTYLE