


Model: 6611XXXX

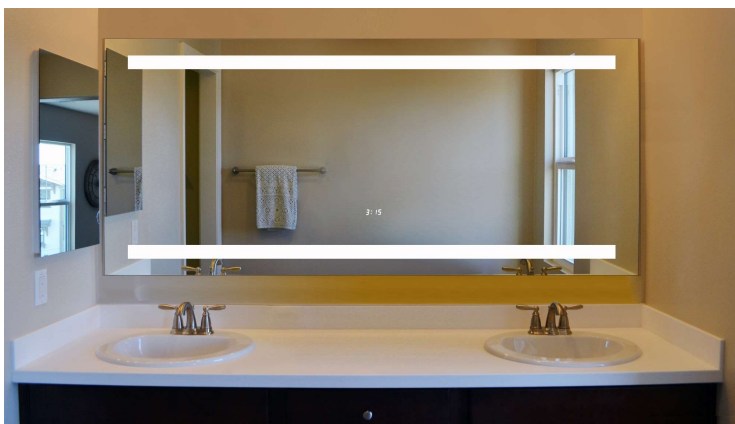

(Items other than the mirror shown in the picture above are not included)

FEATURES

- Energy Efficient and Long-Lasting LED Lighting
- Digital Clock Display
- Dual Switches (Rocker & IR Sensor) for Added Convenience
- Durable Aluminum Frame with Steel Back Panel
- 5mm Copper-Free Mirror
- Surface-Mount with French Cleat
- Hardwired (Junction box required)

LIGHTING

- Front-Facing Lighting
- Average Bulb Life of 50,000 hours
- CRI: 85+
- Color Temperature: 6000K (Daylight)
- Dimmable using Built-in IR Sensor*
- Brightness & Power Consumption: see page 2
- Power Requirements: 110-130V AC, 60Hz


SAFETY

- Safety Backed Mirror
- IP44 Rated
- UL Listed

*** Not compatible with wall dimmer switch.**

OVERVIEW

innoci-usa does not cut corners and only uses the highest quality components and bulbs to make sure that the mirror will be maintenance free and function like the day you purchased for average 50,000 hours of use. **innoci-usa** prides itself on providing unmatched price vs quality for all of our products. All mirrors come with a 5-year limited warranty.

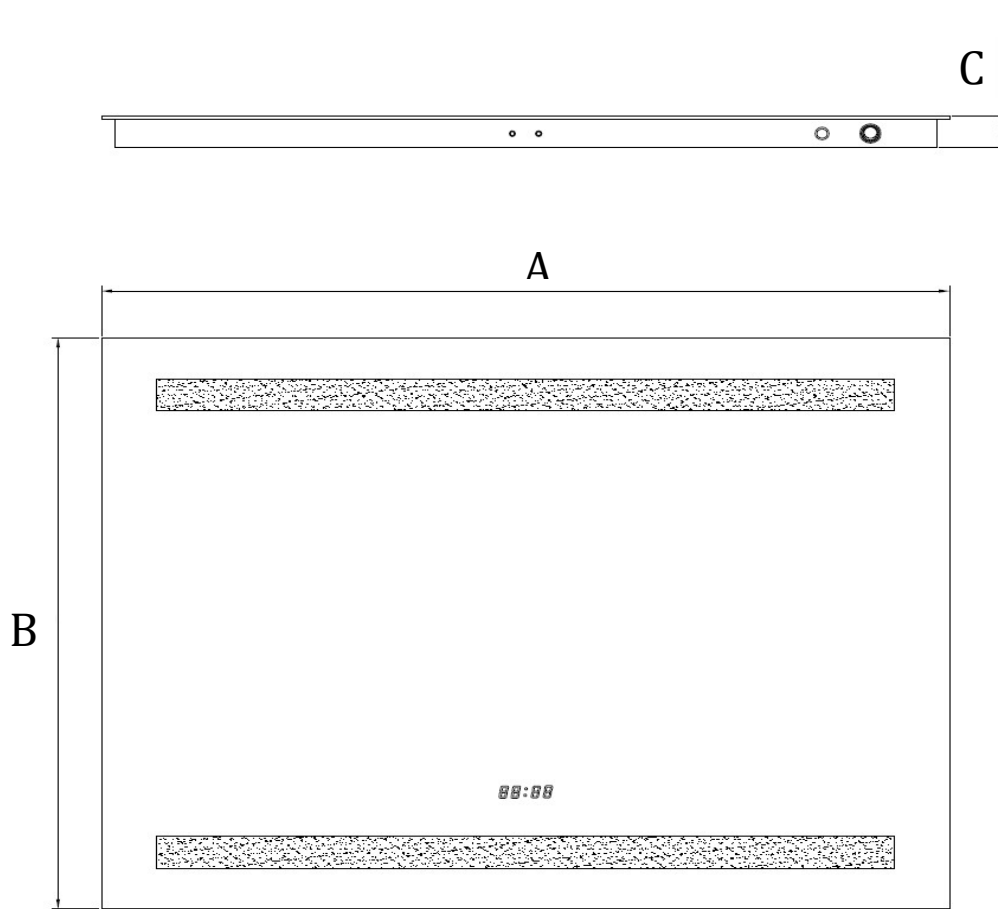

Model #	A	B	C	Brightness (Lumen)	Power Consumption (Watt)
66113828	38	28	1 5/8	4380	35.1
66115036	50	36	1 5/8	5820	46.6
66116428	64	28	1 5/8	7500	50

© **innoci usa, Inc.** All rights reserved.

innoci-usa Inc.
Santa Fe Springs, CA 90670

www.innoci-usa.com
(866) 479-8076

customerservice@innoci-usa.com

innociusa
L I F E S T Y L E

rev1.8