

Model: 6920XXXX



(Items other than the mirror shown in the picture above are not included)

FEATURES

- Energy Efficient and Long-Lasting LED Lighting
- Double Door Mirror Cabinet
- Lighting on Mirror Front & Inside Cabinet
- Double Sides Mirror Door
- Dual Switches (Rocker & IR Sensor) for Added Convenience
- Glass Shelves Included
- Durable Aluminum Frame
- Copper-Free Mirror
- Surface-Mount with French Cleat
- Hardwired (Junction box required)

LIGHTING

- Front-Facing Lighting & Illuminated Interior
- Average Bulb Life of 50,000 hours
- CRI: 85+
- Dimmable using Built-in IR Sensor*
- Brightness & Power Consumption: see page 2
- Power Requirements: 110-130V AC, 60Hz

SAFETY

- IP44 Rated
- UL Listed

*** Not compatible with wall dimmer switch.**


OVERVIEW

innoci-usa does not cut corners and only uses the highest quality components and bulbs to make sure that the mirror will be maintenance free and function like the day you purchased for average 50,000 hours of use. **innoci-usa** prides itself on providing unmatched price vs quality for all of our products. All mirrors come with a 5-year limited warranty.

innoci-usa Inc.
Santa Fe Springs, CA 90670

www.innoci-usa.com
(866) 479-8076

customerservice@innoci-usa.com

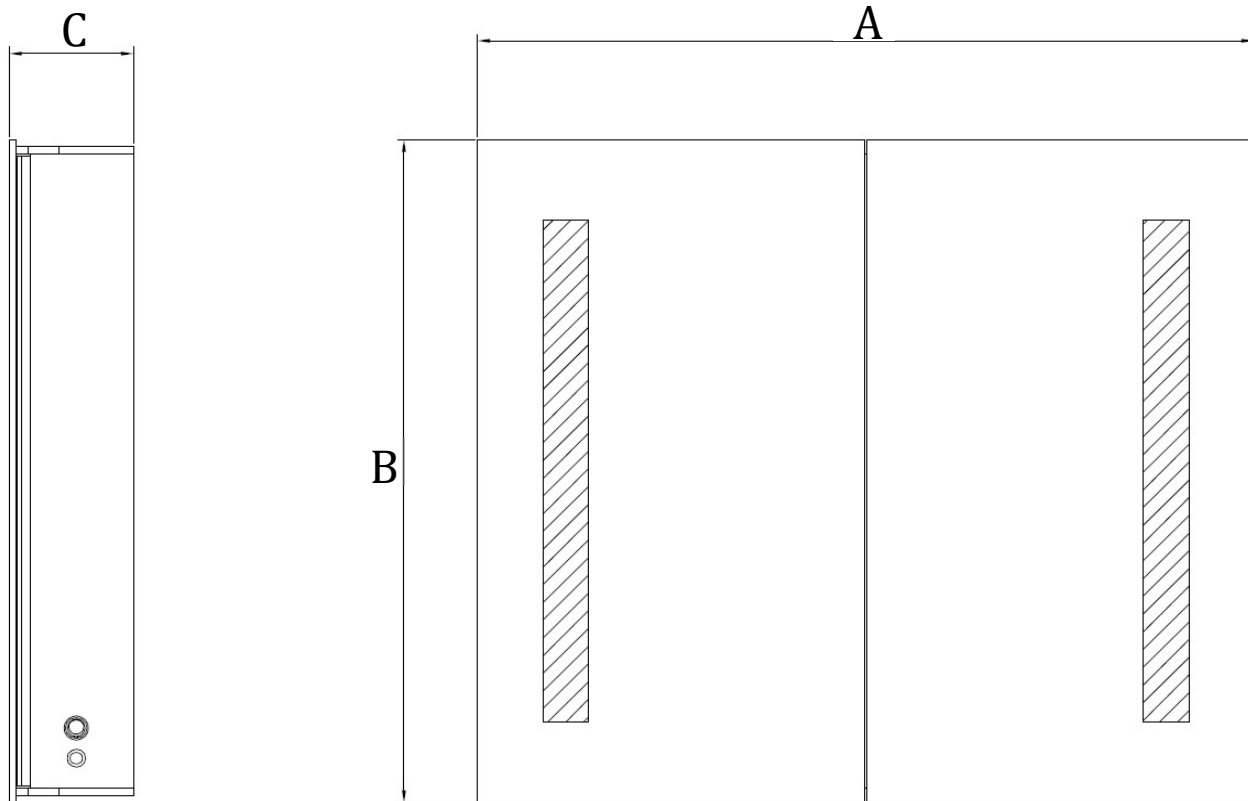

Model #	A	B	C	Brightness (Lumen)	Power Consumption (Watt)
69203026	30	26	4 3/4	2160	35
69204026	40	26	4 3/4	2160	35
69204826	48	26	4 3/4	2160	35

© innoci usa, Inc. All rights reserved.

innoci-usa Inc.
Santa Fe Springs, CA 90670

www.innoci-usa.com
(866) 479-8076

customerservice@innoci-usa.com

innociusa
LIFESTYLE