

**Model: 69233026**



### FEATURES

- Recessed Mounting
- Double-door Medicine Cabinet
- Energy Efficient and Long Lasting LED Lighting
- Aluminum Frame
- Double-side Mirror Door with Built-in 6" Dia. LED Lit Cosmetic Mirror
- 170° Soft-closing Hinges
- Two Adjustable Tempered Glass Shelves
- Rocker Switch
- 3-prong 120V Electrical Outlet
- Mirrored Interior
- Copper-free Mirror

### LIGHTING


- Lighting in Front & Back of Mirror Door
- Average Bulb Life of 50,000 hours
- CRI: 85+
- Color Temperature: 6000K (Daylight)
- Brightness & Power Consumption: see page 2
- Power Requirements: 110-130V AC, 60Hz

### SAFETY

- IP44 Rated

### OVERVIEW

**innoci-usa** does not cut corners and only uses the highest quality components and bulbs to make sure that the mirror will be maintenance free and function like the day you purchased for average 50,000 hours of use. **innoci-usa** prides itself on providing unmatched price vs quality for all of our products. All mirrors come with a 5-year limited warranty.

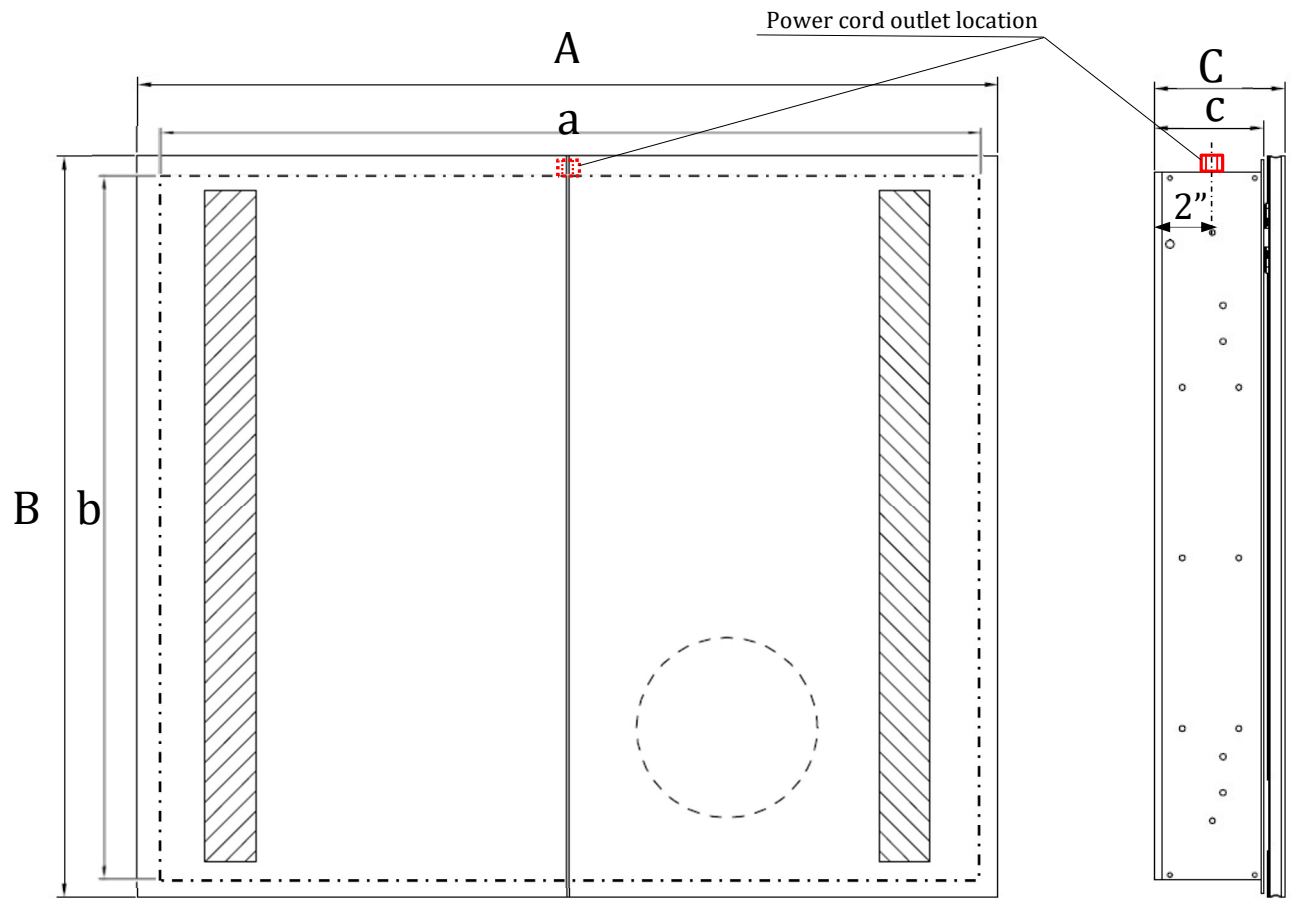

Model #	Overall Dimensions			Rough in Dimensions			Brightness (Lumen)	Power Consumption (Watt)
	A	B	C	a	b	c		
69233026	30	26	4-1/2	29	25	4	1065	17

innoci-usa Inc.  
Santa Fe Springs, CA 90670

[www.innoci-usa.com](http://www.innoci-usa.com)  
(866) 479-8076

[customerservice@innoci-usa.com](mailto:customerservice@innoci-usa.com)

**innociusa**  
LIFESTYLE