

Model: 69252235



FEATURES

- Recessed-Mount or Surface-Mount (Optional Surface-Mount Kit **Sold Separately**)
- Energy Efficient and Long-Lasting LED Lighting
- Aluminum Frame
- Double-side Mirror Door with Built-in 6" Dia. LED Lit Cosmetic Mirror
- Lighting on Both Sides of the Mirror Door
- 170° Soft-closing Hinges
- Three Adjustable Tempered Glass Shelves
- Two Color Temperatures (3000K & 6000K)
- Mirror Front Touch Switch Control
- 3-prong 120V Electrical Outlet (x2)
- USB Outlet (x2)
- Mirrored Interior
- Dimmable LED Lighting
- Copper-free Mirror

LIGHTING


- LED (Light-Emitting Diode)
- Average Bulb Life of 50,000 hours
- Color Temperature: 3000K & 6000K
- Brightness: 6624 Lumen
- Power Consumption: 29.3 Watts

SAFETY

- IP44 Rated

OVERVIEW

Innoci-usa does not cut corners and only uses the highest quality components and bulbs to make sure that the mirror will be maintenance free and function like the day you purchased for average 50,000 hours of use. Innoci-usa prides itself on providing unmatched price vs quality for all of our products. All mirrors come with a 5-year limited warranty.

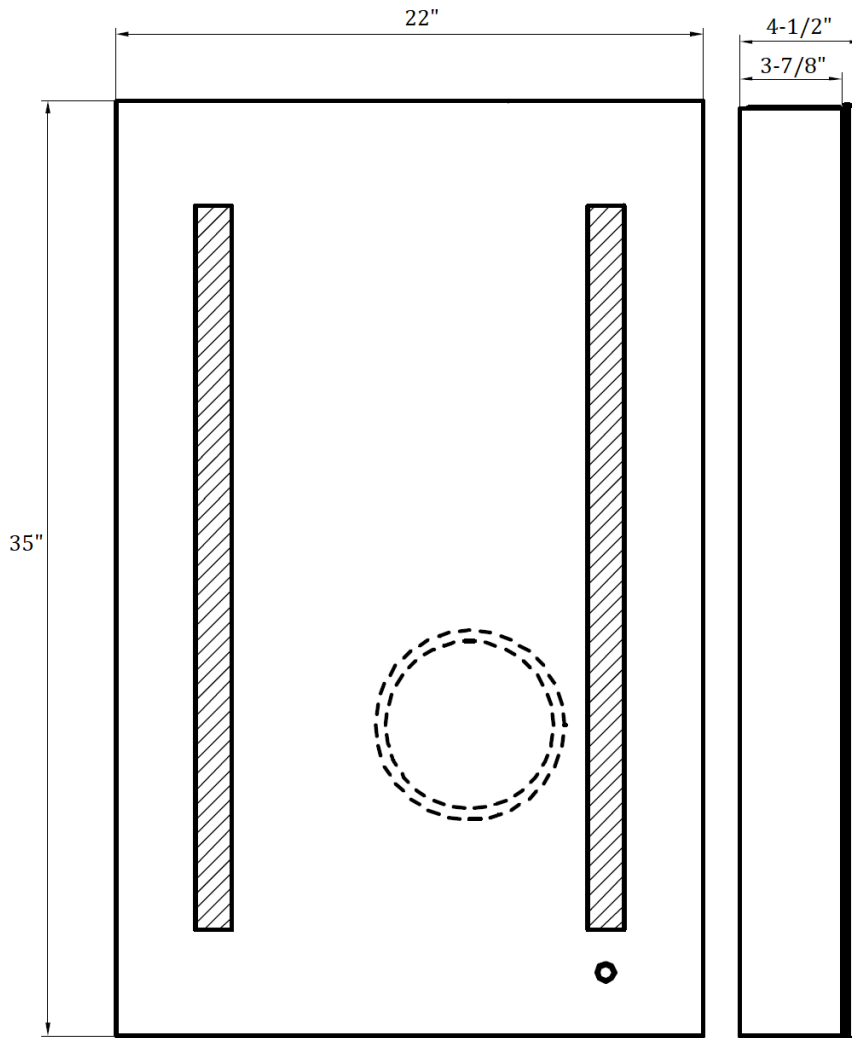

Innoci-USA INC
Santa Fe Springs, CA 90670

www.innoci-usa.com
(866) 479-8076

customerservice@innoci-usa.com

innociusa
LIFESTYLE

Rev. 03.5