

Model: 6940XXXX



FEATURES

- Energy Efficient and Long Lasting LED Lighting
- Single Door Mirror Cabinet
- Double Sided Mirror Door; Lighting on Both Sides
- Glass Shelves Included
- Durable Aluminum Frame
- Built-in Rocker Switch
- Copper-free Mirror
- Surface-Mount with French Cleat
- Hardwired (Junction box required)

LIGHTING


- Front-Facing Lighting
- Average Bulb Life of 50,000 hours
- CRI: 85+
- Color Temperature: 6000K (Daylight)
- Brightness & Power Consumption: see page 2
- Power Requirements: 110-130V AC, 60Hz

SAFETY

- IP44 Rated
- UL Listed

OVERVIEW

innoci-usa does not cut corners and only uses the highest quality components and bulbs to make sure that the mirror will be maintenance free and function like the day you purchased for average 50,000 hours of use. **innoci-usa** prides itself on providing unmatched price vs quality for all of our products. All mirrors come with a 5-year limited warranty.

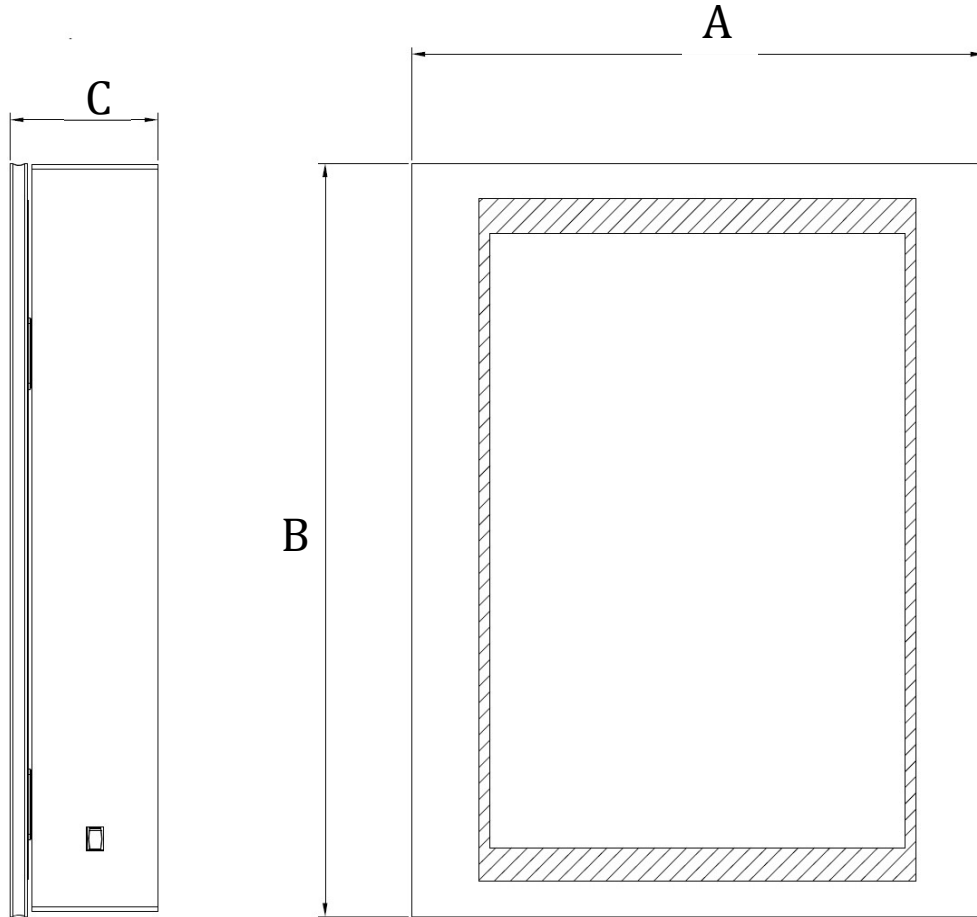

Model #	A	B	C	Brightness (Lumen)	Power Consumption (Watt)
69402026	20	26	5 1/4	1020	17
69402426	24	26	5 1/4	1140	19

innoci-usa Inc.
Newport Beach, CA 92660

www.innoci-usa.com
(866) 479-8076

customerservice@innoci-usa.com

innociusa
LIFESTYLE