

**Model: 81171**



**FEATURES**

- Vitreous china
- One-piece decorative toilet
- High efficiency, low water consumption - Single flush (4.8 LPF/1.27 GPF)
- Elongated front bowl
- Soft-closing seat
- 16-3/4" rim height
- Chrome plated side-mount push button actuator
- Fully glazed 2" Trapway
- 12" rough-in
- 100% factory flush tested
- Floor mount

**COLOR/FINISH**

White

**NOMINAL DIMENSIONS**

28-7/8" (L) x 16-3/8" (W) x 30-1/8" (H)

**COMPONENTS**

Product includes: One-piece Toilet, Tank Cover, Seat w/soft-closing, Wax Ring, Floor Mounting Hardware

**COMPLIANCE**

- cUPC (ASME A112.19.2-2013/CSA B45.1-13)
- EPA WaterSense
- California Energy Commission (Title 20)


**WARRANTY**

1-Year limited warranty


**BEFORE INSTALLATION**

Please make sure the following requirements are met.

1. Minimum distance between finished wall and center of the floor drain should be 12".
2. Minimum distance between the center of the shut-off valve to the center of the drain should be 6-1/2" (FIG 1).

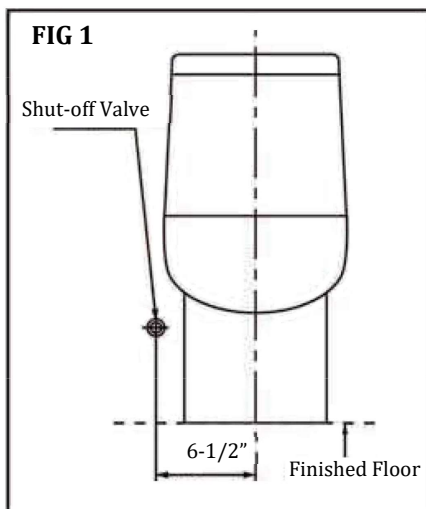

## DIMENSIONS\*

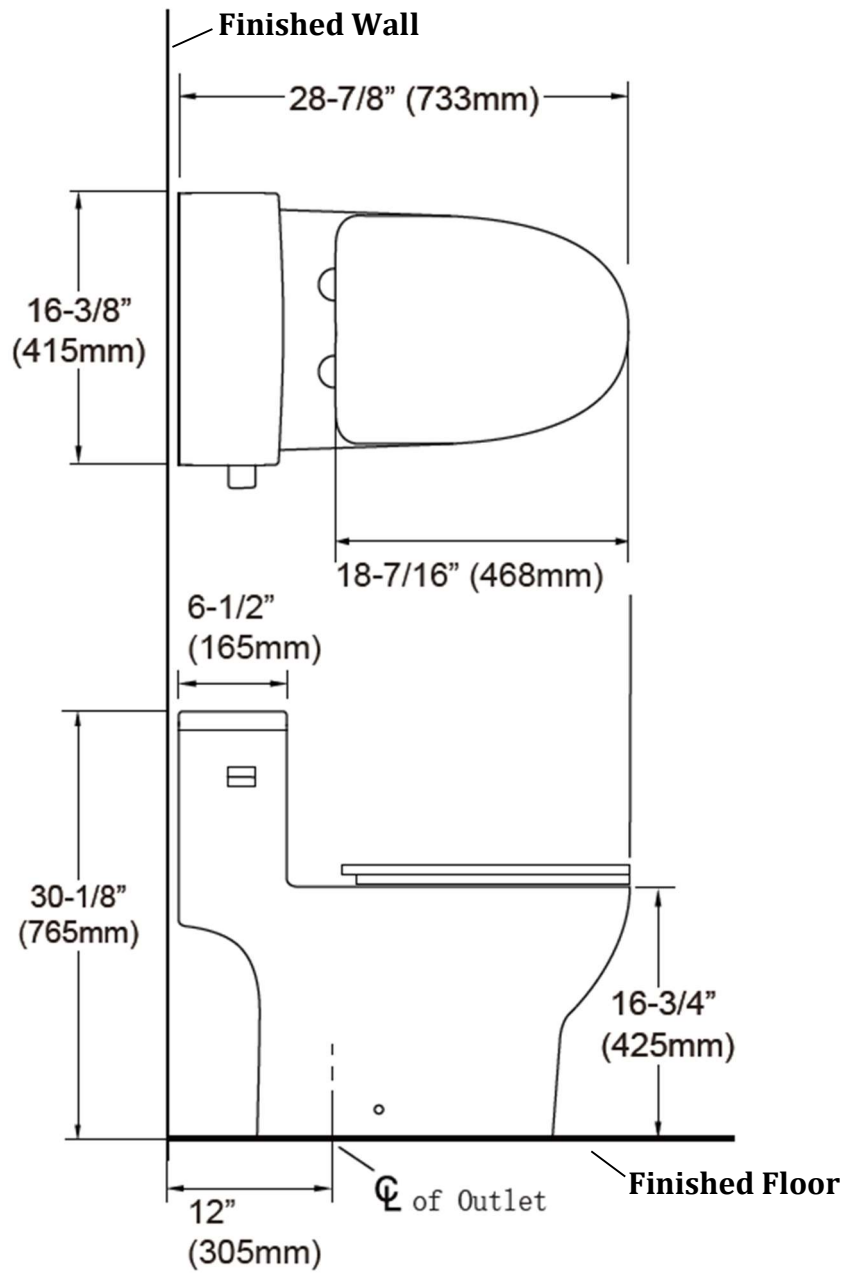

\*Dimensions are for reference only. We reserve the right to change any of the specification without prior notice.