

Model: 81273




FEATURES

- Vitreous china
- One-piece decorative toilet
- High efficiency, low consumption (meets EPA WaterSense criteria)
 - Full flush (4.8 LPF/1.28 GPF)
 - Partial flush (3.0 LPF/0.8 GPF)
- Elongated front bowl
- Soft-closing seat with quick-release for easy cleaning
- 16" rim height
- Chrome plated top mounted push button actuator
- Fully glazed 2" Trapway
- 12" rough-in
- 100% factory flush tested
- Floor mount

BEFORE INSTALLATION

Please make sure the following requirements are met.

1. Minimum distance between finished wall and center of the floor drain should be 12".
2. Minimum distance between the center of the shut-off valve to the center of the drain should be 7-1/2" (FIG 1).

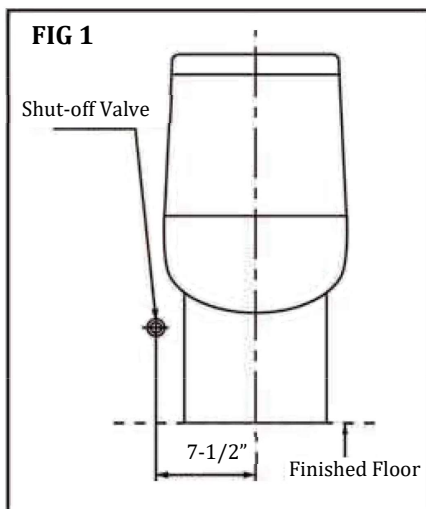

COLOR/FINISH

White

NOMINAL DIMENSIONS

28-3/4" (L) x 14-1/4" (W) x 28-3/4" (H)

COMPONENTS

Product includes: One-piece Toilet, Tank Cover, Seat w/soft-closing and quick release, Wax Ring, Floor Mounting Hardware, Mounting Hole Cover Kit


COMPLIANCE

- cUPC (ASME A112.19.2-2013/CSA B45.1-13 & ASME A112.19.14-2013)
- EPA WaterSense

WARRANTY

1-Year limited warranty

DIMENSIONS*

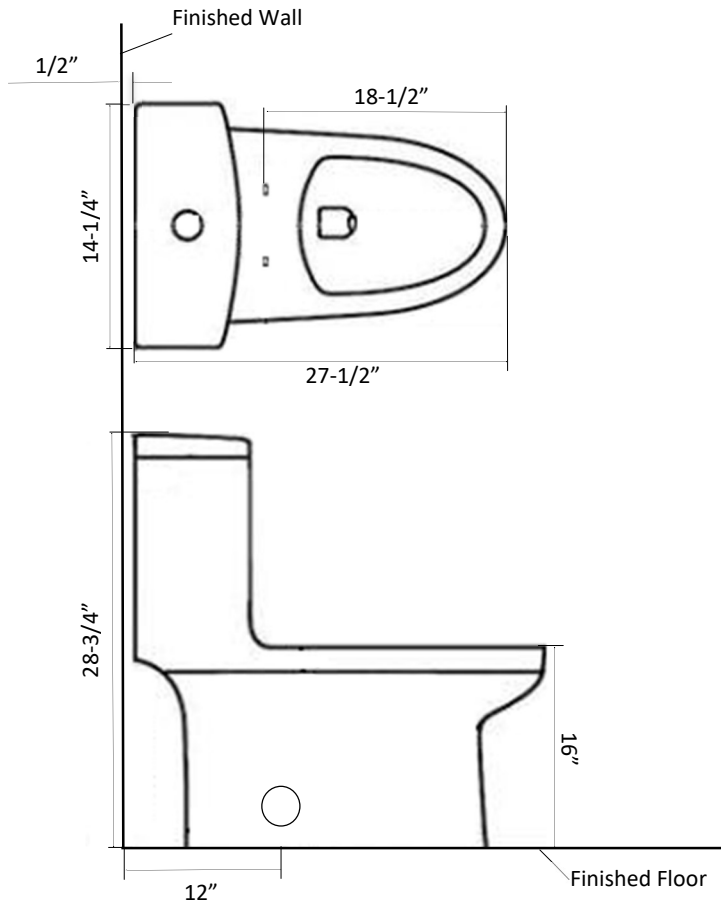

*Dimensions are for reference only. We reserve the right to change any of the specification without prior notice.