

**Model: 81276**



**FEATURES**

- Vitreous china
- One-piece decorative toilet
- High efficiency, low consumption (meets EPA WaterSense criteria)
  - Full flush (5.8 LPF/1.5 GPF)
  - Partial flush (3.9 LPF/1.0 GPF)
- Elongated front bowl
- Soft-closing seat with quick-release for easy cleaning
- 16-1/8" rim height
- Chrome plated top mounted push button actuator
- Fully glazed 2" Trapway
- 12" rough-in
- 100% factory flush tested
- Floor mount

**COLOR/FINISH**

White

**NOMINAL DIMENSIONS**

28-3/8" (L) x 16-1/2" (W) x 28" (H)

**COMPONENTS**

Product includes: One-piece Toilet, Tank Cover, Seat w/soft-closing and quick release, Wax Ring, Floor Mounting Hardware,

**COMPLIANCE**

- cUPC (ASME A112.19.2-2013/CSA B45.1-13 & ASME A112.19.14-2013)
- EPA WaterSense
- California Energy Commission (Title 20)


**WARRANTY**

1-Year limited warranty


**BEFORE INSTALLATION**

Please make sure the following requirements are met.

1. Minimum distance between finished wall and center of the floor drain should be 12".
2. Minimum distance between the center of the shut-off valve to the center of the drain should be 8-1/2" (FIG 1).

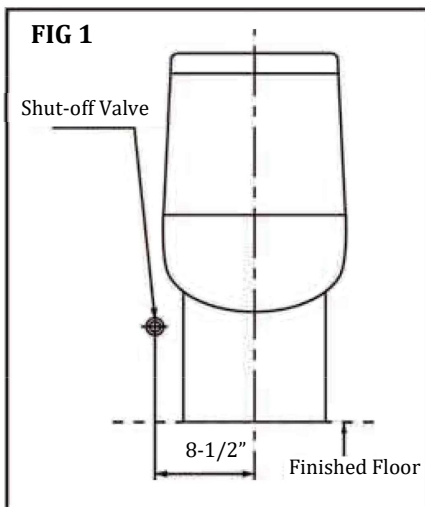

## DIMENSIONS\*

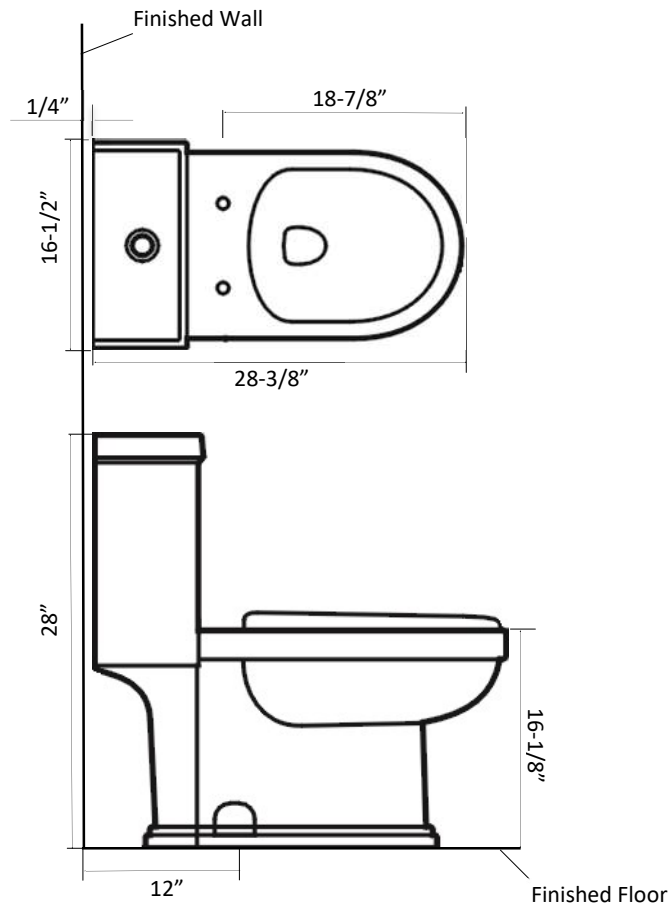

\*Dimensions are for reference only. We reserve the right to change any of the specification without prior notice.